


Part Number: [0002061132](#)
Status: Active
Overview: Standard .062" Pin and Socket Power Connectors
Description: 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Series 1855, Female, with Tin (Sn) Plated Brass Contact, 24-30 AWG, Bag

Documents:

[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[Packaging Specification PK-1190-003 \(PDF\)](#)

일반적 특성	
적용제품	Power
Crimp Quality Equipment	Yes
전체보기	<u>Standard .062" Pin and Socket Power Connectors</u>
Packaging Alternative	<u>02-06-1131 (Reel)</u>
제품명	Standard .062"
UPC	800753616042
물리적 특성	
암수구분	암
원재료 - 메탈	황동
원재료 - 도금부	주석
원재료 - 도금부 터미네이션	주석
Net Weight	0.130/g
포장타입	백 (Bag)
최소도금: 결합	0.508µm
최소 도금: 터미네이션	0.508µm
터미네이션 결합방식	크림프 또는 압착
와이어 절연 두께	1.02-2.29mm
와이어 사이즈 (AWG)	24, 26, 28, 30
와이어 사이즈 mm ²	N/A
원재료 정보	
Engineering Number	1855-(P901)L
참고 - 도면번호	
Packaging Specification	PK-1190-003
도면	SD-1855-*

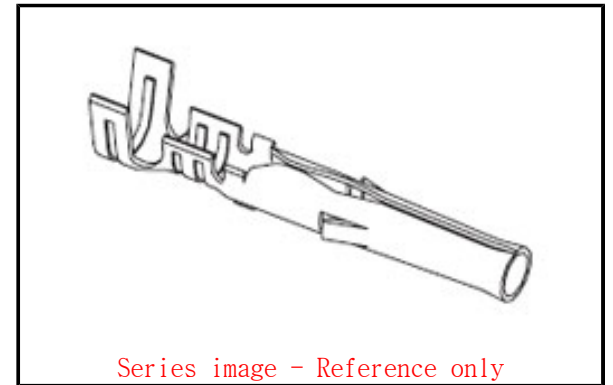

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status
Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[1855](#) Series