


Part Number: [0039000038](#)
 Status: Active
 Overview: [Mini-Fit Jr. Power Connectors](#)
 Description: Mini-Fit Female Crimp Terminal, Tin (Sn) over Copper (Cu) Plated Brass, 18-24 AWG, Reel

Documents:

도면 (PDF)	Packaging Specification PK-5556-001-001 (PDF)
제품규격 PS-5556-001-001 (PDF)	Test Summary 55560000-TS-000 (PDF)
제품규격 PS-5556-002-001 (PDF)	RoHS 증명서(PDF)
제품규격 TS-5556-002-001 (PDF)	

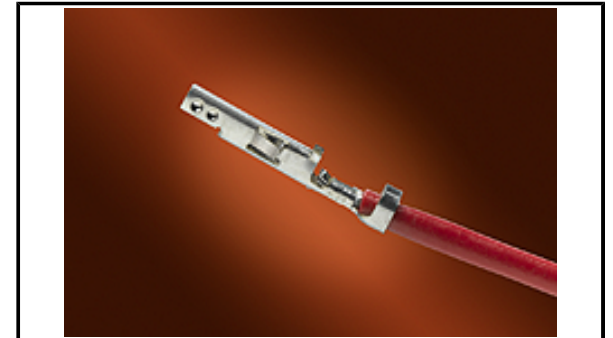

Series image - Reference only

일반적 특성	
적용제품	Power, 와이어 대 보드, 와이어 대 와이어
Crimp Quality Equipment	Yes
전체보기	Mini-Fit Jr. Power Connectors
Packaging Alternative	39-00-0039 (Loose)
제품명	Mini-Fit
UPC	800753585010
물리적 특성	
내구성(최대 메이팅 사이클)	30
암수구분	암
원재료 - 메탈	황동
원재료 - 도금부	주석
원재료 - 도금부 터미네이션	주석
Net Weight	0.453/g
포장타입	릴 (Reel)
최소도금: 결합	0.889µm
최소 도금: 터미네이션	0.889µm
터미네이션 결합방식	크림프 또는 압착
와이어 절연 두께	1.30-3.10mm
와이어 사이즈 (AWG)	18, 20, 22, 24
와이어 사이즈 mm ²	N/A
전기적 특성	
전류 - 접촉 당 최대 출력	9.0A
최대전압	600V
납땜 프로세스 정보	
Lead-freeProcess Capability	N/A
원재료 정보	
Engineering Number	5556T
참고 - 도면번호	
Packaging Specification	PK-5556-001-001
제품규격	PS-5556-001-001, PS-5556-002-001, TS-5556-002-001
도면	55560000-SD-000
Test Summary	55560000-TS-000

EU ELV
Compliant

EU RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status
Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[5556 Series](#)

Mates With
[5558](#) Mini-Fit Crimp Male Terminals,
Mini-Fit Jr. Header, Dual Row, [5566](#) ,
[5569](#)

Use With
[5557](#) Mini-Fit Jr. Receptacle Housing,
[30067](#) Mini-Fit TPA, [42474](#) Mini-Fit BMI
Panel Mount