


Part Number: [0391001810](#)
Status: Active
Overview: Eurostyle Two-Screw Barrier Strips
Description: 8.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 10 Circuits

Documents:

[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)

일반적 특성	
적용제품	와이어 대 와이어
부품형태	One Piece
전체보기	Eurostyle Two-Screw Barrier Strips
제품명	Eurostyle Two Screw
타입	배리어 스트립
UPC	78172545128
물리적 특성	
회로수	10
최대 회로수	10
색상 - Resin	흰색
삽입각도	수평
결합제품 잠금장치	없음
원재료 - 메탈	스테인레스 스틸
원재료 - 플라스틱	나일론 (PA)
Net Weight	26.880/g
열 수	2
방향성	수직
PCB 유지력	Yes
패널마운트	서킷 사이의 설치구멍
피치 - 결합부	8.00mm
피치 - 터미널 간격	8.00mm
결합제품 오삽입 장치	No
End-to-End 연결형	No
사용온도 범위	-40° to +105°C
와이어 사이즈 (AWG)	12, 14, 16, 18, 20, 22
전기적 특성	
전류 - 접촉 당 최대 출력	20.0A
최대전압	600V
원재료 정보	
Engineering Number	M800-01-10-5-M1
참고 - 도면번호	
도면	SD-39100-011

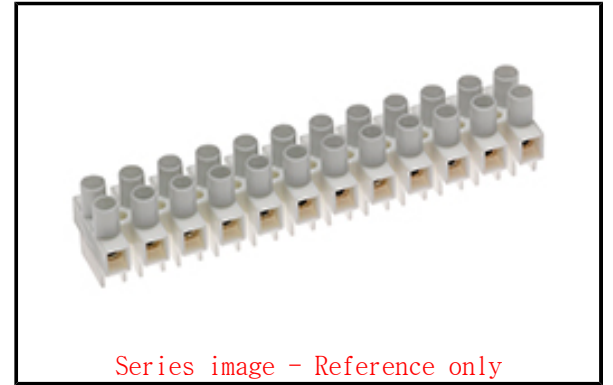

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant with
Exemption 6(c)
REACH SVHC

Contained Per -
ED/61/2018 (27 June
2018)

납
Halogen-Free
Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
Prop65	Duty-To-Declare
PropRisk	Cancer
PropRisk	Developmental toxicity
PropRisk	Reproductive toxicity
PropSub	Lead and its compounds
RoHS Phthalates	Not Contained

Search Parts in this Series
[39100 Series](#)