


Part Number: [0430300007](#)
 Status: Active
 Overview: [Micro-Fit 3.0 Connector System Product Family](#)
 Description: Micro-Fit 3.0 Crimp Terminal, Female, with Tin (Sn) Plated Phosphor Bronze Contact, 20-24 AWG, Bag

Documents:

도면 (PDF)	Packaging Specification PK-43030-003 (PDF)
3D 모델	RoHS 증명서(PDF)
제품규격 PS-43045 (PDF)	Product Literature (PDF)
제품규격 PS-43045-001 (PDF)	

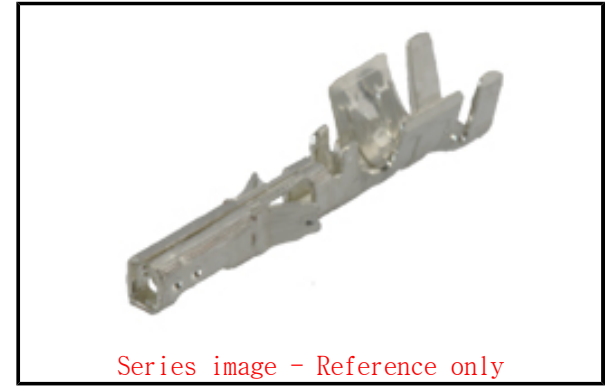

일반적 특성	
적용제품	Power, 와이어 대 보드, 와이어 대 와이어
Crimp Quality Equipment	Yes
전체보기	Micro-Fit 3.0 Connector System Product Family
Packaging Alternative	43030-0001 (Reel)
Product Literature Order No	987650-5984
제품명	Micro-Fit 3.0
UPC	800753755772
물리적 특성	
암수구분	암
원재료 - 메탈	인칭동
원재료 - 도금부	주석
원재료 - 도금부 터미네이션	주석
Net Weight	0.061/g
포장타입	백 (Bag)
최소도금: 결합	1.016µm
최소 도금: 터미네이션	1.016µm
터미네이션 결합방식	크림프 또는 압착
와이어 절연 두께	1.85mm max.
와이어 사이즈 (AWG)	20, 22, 24
와이어 사이즈 mm ²	N/A
전기적 특성	
전류 - 접촉 당 최대 출력	8.5A
납땜 프로세스 정보	
Lead-freeProcess Capability	N/A
원재료 정보	
참고 - 도면번호	
Packaging Specification	PK-43030-003
제품규격	PS-43045, PS-43045-001
도면	SD-43030-****

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status
Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[43030](#) Series

Use With
[43025](#) , [43645](#) Micro-Fit 3.0 Receptacle
Housings, [44133](#) Micro-Fit BMI Panel
Mount Receptacle Housings