


**Part Number:** [0462350001](#)  
**Status:** Active  
**Overview:** [Micro-Fit 3.0 Connector System Product Family](#)  
**Description:** Micro-Fit RMF Reduced Mating Force, Crimp Terminal, Female, with 0.38µm Selective Gold (Au) over Nickel (Ni), 20-24 AWG, without Lubricant

**Documents:**

<a href="#">도면 (PDF)</a>	<a href="#">Packaging Specification PK-46235-001 (PDF)</a>
<a href="#">제품규격 PS-46235-001-001 (PDF)</a>	<a href="#">RoHS 증명서(PDF)</a>
<a href="#">제품규격 TS-46235-001-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

일반적 특성	
적용제품	Power, 와이어 대 보드, 와이어 대 와이어
설명	Up to 50% reduction in mating force
Crimp Quality Equipment	Yes
전체보기	<a href="#">Micro-Fit 3.0 Connector System Product Family</a>
Product Literature Order No	987650-5984
제품명	Micro-Fit RMF
UPC	800756683485
물리적 특성	
내구성(최대 메이팅 사이클)	40
암수구분	암
원재료 - 메탈	구리-아연-주석
원재료 - 도금부	금
원재료 - 도금부 터미네이션	니켈
Net Weight	0.046/g
포장타입	릴 (Reel)
최소도금: 결합	0.381µm
최소 도금: 터미네이션	1.270µm
터미네이션 결합방식	크림프 또는 압착
와이어 절연 두께	1.85mm max.
와이어 사이즈 (AWG)	20, 22, 24
와이어 사이즈 mm <sup>2</sup>	N/A
전기적 특성	
전류 - 접촉 당 최대 출력	5.0A
납땜 프로세스 정보	
Lead-freeProcess Capability	N/A
원재료 정보	
참고 - 도면번호	
Packaging Specification	PK-46235-001
제품규격	PS-46235-001-001, TS-46235-001-001
도면	SD-46235-001

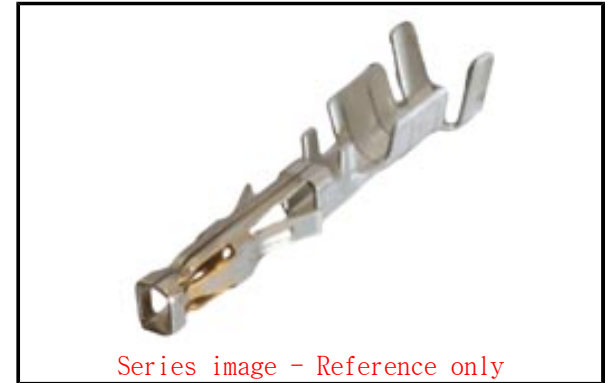

EU ELV  
**Compliant**

EU RoHS China RoHS  
**Compliant**

REACH SVHC  
Not Contained Per -  
ED/61/2018 (27 June  
2018)

Halogen-Free  
Status  
**Low-Halogen**

For more information, please visit  
[Contact US](#)

China ROHS Green Image  
ELV Compliant  
RoHS Phthalates Not Contained

Search Parts in this Series  
[46235](#) Series

Mates With  
[43031](#) Micro-Fit 3.0 Male Crimp  
Terminals

Use With  
[43025](#) , [43645](#) Micro-Fit 3.0 Receptacle  
Housings, [44133](#) Micro-Fit BMI Panel  
Mount Receptacle Housings