

Part Number: [0502128100](#)
Status: Active
Description: 2.00mm Pitch Crimp Terminal, Female, 24-30 AWG, Bag

Documents:

3D 모델	제품규격 PS-51160-001 (PDF)
도면 (PDF)	제품규격 PS-51160-006-001 (PDF)
제품규격 PS-51065-005 (PDF)	제품규격 PS-51225-003-001 (PDF)
제품규격 PS-51065-016-001 (PDF)	제품규격 PS-52968-006-001 (PDF)
제품규격 PS-51065-017-001 (PDF)	제품규격 PS-52968-007-001 (PDF)
제품규격 PS-51065-018-001 (PDF)	제품규격 PS-53717-002-001 (PDF)
제품규격 PS-51089-001 (PDF)	제품규격 PS-54111-002-001 (PDF)
제품규격 PS-51089-005-001 (PDF)	제품규격 PS-54214-001 (PDF)
제품규격 PS-51090-003 (PDF)	제품규격 PS-54452-007-001 (PDF)
제품규격 PS-51090-004-001 (PDF)	제품규격 PS-55533-004-001 (PDF)
제품규격 PS-51090-005-001 (PDF)	Application Specification 510900001-000 (PDF)
제품규격 PS-51090-009 (PDF)	Packaging Specification SPK-50212-001-001 (PDF)
제품규격 PS-51090-016-001 (PDF)	RoHS 증명서(PDF)
제품규격 PS-51090-017-001 (PDF)	Product Literature (PDF)
제품규격 PS-51090-018-001 (PDF)	


일반적 특성	
적용제품	Signal, 와이어 대 보드
Crimp Quality Equipment	Yes
Packaging Alternative	50212-8000 (Reel)
Product Literature Order No	987651-8983
제품명	DuraClik, Mi II, Micro-Latch, Sherlock
UPC	800754369473

물리적 특성	
암수구분	암
원재료 - 메탈	인칭동
원재료 - 도금부	주석
원재료 - 도금부 터미네이션	주석
Net Weight	20.400/mg
포장타입	백 (Bag)
터미네이션 결합방식	크림프 또는 압착
와이어 절연 두께	1.40mm max.
와이어 사이즈 (AWG)	24, 26, 28, 30
와이어 사이즈 mm ²	N/A

전기적 특성	
전류 - 접촉 당 최대 출력	2.0A
최대전압	125V

원재료 정보

참고 - 도면번호	
Application Specification	510900001-000
Crimp Specification	CS-50212
Packaging Specification	SPK-50212-001-001
제품규격	PS-51065-005, PS-51065-016-001, PS-51065-017-001, PS-51065-018-001, PS-51089-001, PS-51089-005-001, PS-51090-003, PS-51090-004-001, PS-51090-005-001, PS-51090-009, PS-51090-016-001, PS-51090-017-001, PS-51090-018-001, PS-51160-001, PS-51160-006-001, PS-51225-003-001, PS-52968-006-001, PS-52968-007-001, PS-53717-002-001,

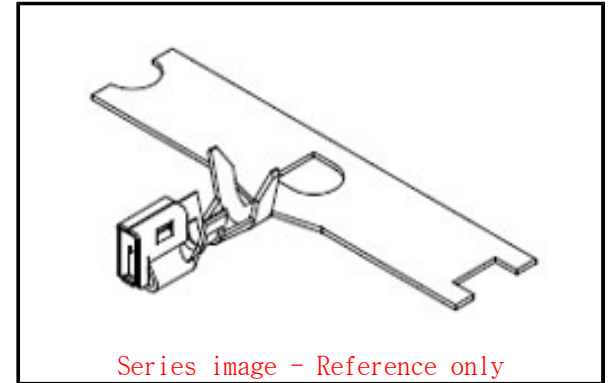

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[50212 Series](#)

Use With
DuraClik Receptacle Housing [502351](#)

Micro-Latch Receptacle Housing
[51065](#)
Mi II Receptacle Housings
[51089](#) , [51090](#)

PS-54111-002-001, PS-54214-001, PS-54452-007-001,
PS-55533-004-001
SD-50212-001

This document was generated on 09/12/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION