


Part Number: [0151660427](#)
 Status: Active
 Overview: Premo-Flex Cable Jumpers
 Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 40 Circuits, 0.05m Cable Length, Tin (Sn) Plating

Documents:

도면 (PDF)	RoHS 증명서(PDF)
제품규격 PS-15166-001-001 (PDF)	Product Literature (PDF)
Packaging Specification PK-15166-001-001 (PDF)	

일반적 특성	
설명	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
전체보기	Premo-Flex Cable Jumpers
Product Literature Order No	987650-6631
제품명	Premo-Flex FFC Jumper
UPC	884982849259
물리적 특성	
케이블 길이	0.051m
회로수	40
최대 회로수	40
Net Weight	1.000/g
포장타입	백 (Bag)
피치 - 터미널 간격	0.50mm
사용온도 범위	-40° to +105°C
와이어 사이즈 (AWG)	N/A
와이어/케이블 타입	플랫 플렉스 케이블
전기적 특성	
전류 - 접촉 당 최대 출력	0.5A
최대전압	60V AC
원재료 정보	
참고 - 도면번호	
Packaging Specification	PK-15166-001-001
제품규격	PS-15166-001-001
도면	SD-15166-001

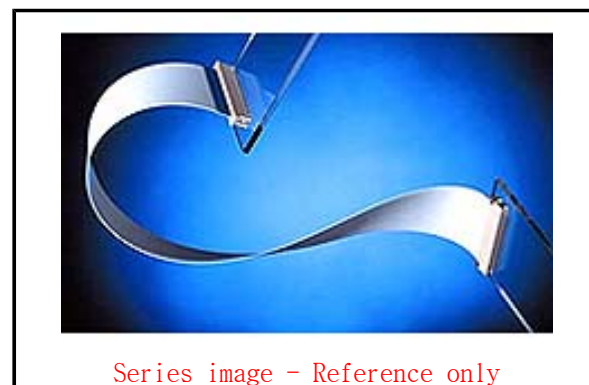

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free Status	
Not Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[15166 Series](#)

Use With
[Molex FFC - FPC connector](http://www.molex.com/product/ffc). Be sure to match like plating.