

Part Number: [0022057035](#)
Status: Active
Overview: [Mini-SPOX Wire-to-Board Connector System](#)
Description: 2.50mm Pitch Mini-SPOX Wire-to-Board Header, Right-Angle, Shrouded, Friction Lock, 3 Circuits

Documents:

[3D 모델](#) [Packaging Specification SPK-5268-001-001 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서 \(PDF\)](#)
[제품규격 PS-5264-001-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

일반적 특성


적용제품 Signal, 와이어 대 보드
 전체보기 [Mini-SPOX Wire-to-Board Connector System](#)
 제품명 Mini-SPOX
 UPC 800753592766

물리적 특성

분리형 No
 회로수 3
 최대 회로수 3
 색상 - Resin Natural
 내구성(최대 메이팅 사이클) 30
 First Mate / Last Break No
 난연성 94V-0
 Glow-Wire Capable No
 결합제품 가이드 No
 Keying to Mating Part 없음
 결합제품 잠금장치 Yes
 원재료 - 도금부 주석
 원재료 - 도금부 터미네이션 주석
 원재료 - 플라스틱 나일론 (PA)
 Net Weight 344.400/mg
 열 수 1
 방향성 직각
 PC 테일길이 3.50mm
 PCB 고정위치 No
 PCB 유지력 없음
 PCB Thickness - Recommended 1.60mm
 포장타입 백 (Bag)
 피치 - 결합부 2.50mm
 최소도금: 결합 4.064µm
 최소 도금: 터미네이션 4.064µm
 결합제품 오삽입 장치 Yes
 PCB 오삽입 장치 No
 덮개 폴리형
 End-to-End 연결형 No
 표면실장호환성 (SMC) No
 사용온도 범위 -40° to +105°C
 터미네이션 결합방식 스루홀

전기적 특성

전류 - 접촉 당 최대 출력 3.0A

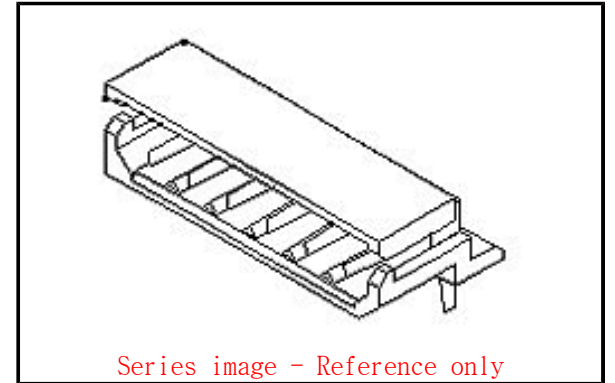

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS [China RoHS](#)

Compliant
[REACH SVHC](#)
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

[Halogen-Free](#)
 Status

Not Low-Halogen
 Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS [Green Image](#)
 ELV [Not Relevant](#)
 Prop65 [Compliant](#)
 RoHS Phthalates [Not Contained](#)

Search Parts in this Series
[5268 Series](#)

Mates With
[5264 Mini-SPOX Wire-to-Board Crimp](#)
 Housing

최대전압	250V
원재료 정보 Engineering Number	5268-03A
참고 - 도면번호 Packaging Specification	SPK-5268-001-001
제품규격	PS-5264-001-001
도면	SD-5268-NA

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION