


Part Number: [0470541000](#)
Status: Active
Overview: [KK@ Interconnect System - Molex](#)
Description: KK 254 Housing with Polarization Rib, 4 Pin

Documents:

[3D 모델](#) [Packaging Specification 470541000-PK-000 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[제품규격 PS-47053-001-001 \(PDF\)](#)

Agency Certification

UL	E29179
일반적 특성	
적용제품	Signal, 와이어 대 보드
전체보기	KK@ Interconnect System - Molex
제품명	KK 254
UPC	822348237999
물리적 특성	
최대 회로수	4
색상 - Resin	아이보리
난연성	94V-0
암수구분	리셉터클
Glow-Wire Capable	No
결합제품 잠금장치	Yes
원재료 - 플라스틱	나일론 (PA)
Net Weight	0.522/g
열 수	1
포장타입	백 (Bag)
패널마운트	No
피치 - 결합부	2.54mm
피치 - 터미널 간격	2.54mm
결합제품 오삽입 장치	Yes
End-to-End 연결형	No
사용온도 범위	See Product Specification
전기적 특성	
전류 - 접촉 당 최대 출력	4.0A
납땜 프로세스 정보	
Duration at Max. Process Temperature (seconds)	005
Lead-free Process Capability	N/A
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	230
원재료 정보	
참고 - 도면번호	
Packaging Specification	470541000-PK-000
제품규격	PS-47053-001-001
도면	SD-47054-001

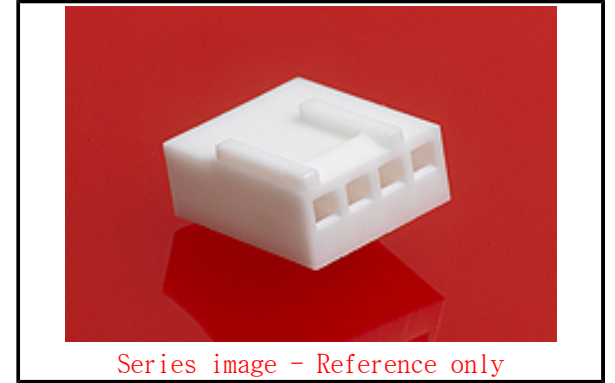

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[47054](#) Series

Mates With
[47053](#) 2.54mm Pitch KK Vertical Header,
with Friction Lock

Use With
[2759](#) KK Crimp Terminal, 22-30 AWG