


Part Number: [0475530001](#)
Status: Active
Overview: [SIM and Combo Card Connectors](#)
Description: 1.27mm Pitch SIM Card Holder with 2 Detect Pins, 6 Circuits, Push-Push Style, Housing Height 1.80mm, without Pegs, Lead-Free

Documents:

[3D 모델](#) [Packaging Specification PK-47553-001 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[제품규격 PS-47553-201-001 \(PDF\)](#)

일반적 특성	
설명	Without Pegs
전체보기	SIM and Combo Card Connectors
제품명	mini-SIM
스타일	Push-Push
UPC	822350925761
물리적 특성	
카드검출 스위치	개방형
Card Entry Location	프런트
회로수	6
최대 회로수	6
내구성(최대 메이팅 사이클)	2500
취출 버튼	N/A
원료 - 컨택부	Copper Alloy
원재료 - 도금부	Gold over Nickel
원재료 - 도금부 터미네이션	금
원재료 - 플라스틱	고내열 수지 (플라스틱)
Material - Shell	스테인레스 스틸
Net Weight	1.613/g
PCB 고정위치	No
PCB 유지력	Yes
포장타입	엠보스트 테이프 / 릴
피치 - 결합부	2.54mm
피치 - 터미널 간격	1.27mm
사용온도 범위	-40° to +85°C
터미네이션 결합방식	표면실장
전기적 특성	
전류 - 접촉 당 최대 출력	0.5A
차폐형	Yes
최대전압	50V DC
납땜 프로세스 정보	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	250
원재료 정보	
참고 - 도면번호	
Packaging Specification	PK-47553-001
제품규격	PS-47553-201-001
도면	SD-47553-001

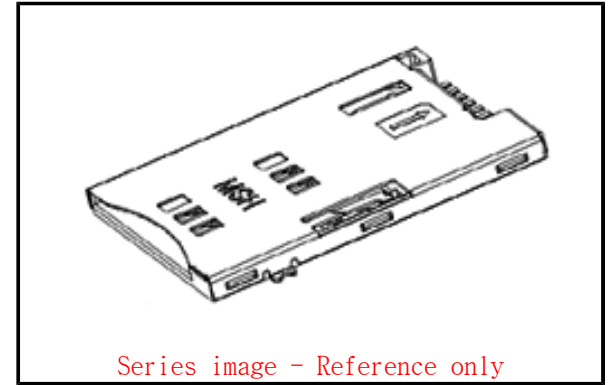

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -	
ED/61/2018 (27 June	
2018)	
Halogen-Free	
Status	
Not Low-Halogen	
Need more information on product	
environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for	
any non-product compliance questions.	
China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[47553 Series](#)

Mates With
Standard SIM Card

This document was generated on 09/12/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION