

Part Number: [0510650400](#)
Status: Active
Description: 2.00mm Pitch Micro-Latch Wire-to-Board Housing, Friction Lock, 4 Circuits, Natural

Documents:

3D 모델	제품규격 PS-51065-017-001 (PDF)
도면 (PDF)	제품규격 PS-51065-018-001 (PDF)
제품규격 510650000-000 (PDF)	Packaging Specification SPK-51065-001-001 (PDF)
제품규격 PS-51065-005 (PDF)	RoHS 증명서(PDF)
제품규격 PS-51065-016-001 (PDF)	Product Literature (PDF)

Agency Certification

CSA	LR19980
UL	E29179

일반적 특성

적용제품 Signal, 와이어 대 보드

Product Literature Order No	987651-8983
제품명	Micro-Latch
UPC	800753642676


물리적 특성

최대 회로수	4
색상 - Resin	Natural
난연성	94V-0
암수구분	리셉터클
Glow-Wire Capable	No
원재료 - 플라스틱	Polyester
Net Weight	113.800/mg
열 수	1
포장타입	백 (Bag)
패널마운트	No
피치 - 결합부	2.00mm
End-to-End 연결형	No
사용온도 범위	-40° to +105°C

원재료 정보

참고 - 도면번호

Packaging Specification	SPK-51065-001-001
제품규격	510650000-000, PS-51065-005, PS-51065-016-001, PS-51065-017-001, PS-51065-018-001
도면	SD-51065-004, SD-51065-006

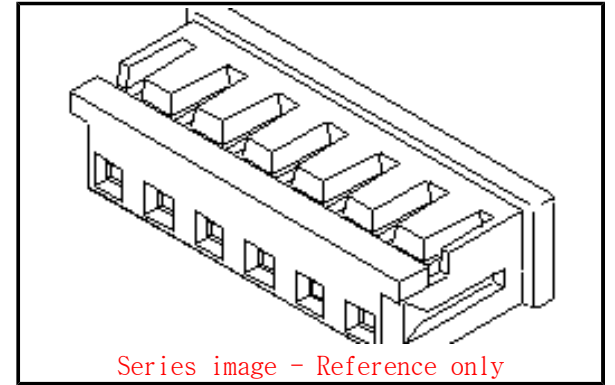

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Prop65

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Compliant

Not Contained

Search Parts in this Series
[51065 Series](#)

Mates With
[53253 PCB Header](#), [53254 PCB Header](#)

Use With
[50212 Crimp Terminal](#)