

Part Number: [0522071060](#)
Status: Active
Overview: [FFC-FPC \(SMT\)](#)
Description: 1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Top Contact Style Receptacle, 10 Circuits, Gold (Au) Contact Plating, High Barrier Packaging

Documents:

[3D 모델](#) [Packaging Specification SPK-52207-002-001 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[제품규격 PS-52207-048-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

일반적 특성

전체보기 [FFC-FPC \(SMT\)](#)
 제품명 Easy-On
 UPC 822350133500

물리적 특성

Actuator Type Slider
 회로수 10
 색상 - Resin Natural
 결합위치 상부
 내구성(최대 메이팅 사이클) 30
 난연성 94V-0
 Mated Height 2.70mm
 원재료 - 메탈 인칭동
 원재료 - 도금부 금
 원재료 - 도금부 터미네이션 주석
 원재료 - 플라스틱 나일론 (PA)
 Net Weight 428.620/mg
 열 수 1
 방향성 직각
 PC 테일길이 2.00mm
 PCB 고정위치 No
 PCB 마운팅 표면실장
 PCB 유지력 Yes
 포장타입 엠보스트 테이프 / 릴
 피치 - 결합부 1.00mm
 피치 - 터미널 간격 1.00mm
 PCB 오삽입 장치 Yes
 End-to-End 연결형 No
 사용온도 범위 -30° to +85°C
 와이어/케이블 타입 FFC/FPC


전기적 특성

전류 - 접촉 당 최대 출력 1.0A
 최대전압 125V

원재료 정보

참고 - 도면번호

Packaging Specification SPK-52207-002-001
 제품규격 PS-52207-048-001
 도면 SD-52207-064-001, SD-52207-065

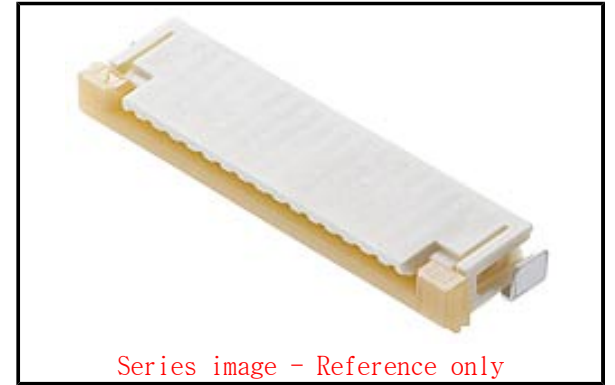

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS

ELV

Prop65

RoHS Phthalates

Green Image

Not Relevant

Compliant

Not Contained

Search Parts in this Series
[52207 Series](#)

Mates With

http://www.molex.com/product/premoflex_ffc-fpc.html>Molex Premo-Flex FFC. Be sure to match like plating

This document was generated on 09/11/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION