

Part Number: [0533980871](#)
Status: Active
Overview: [PicoBlade Connector System](#)
Description: 1.25mm Pitch PicoBlade Header, Surface Mount, Vertical, 8 Circuits

Documents:

[3D 모델](#) [Packaging Specification SPK-53398-002-001 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[제품규격 PS-51021-024-001 \(PDF\)](#)


Agency Certification

UL E29179
일반적 특성
적용제품 Signal, 와이어 대 보드
Current Derating Order No 987651-3691
전체보기 [PicoBlade Connector System](#)
제품명 PicoBlade
UPC 822348164356

물리적 특성
분리형 No
회로수 8
최대 회로수 8
색상 - Resin Natural
내구성(최대 메이팅 사이클) 30
First Mate / Last Break No
난연성 94V-0
Glow-Wire Capable No
결합제품 가이드 No
결합제품 잠금장치 Yes
Mated Height 5.70mm
원재료 - 메탈 인칭동
원재료 - 도금부 주석
원재료 - 도금부 터미네이션 주석
원재료 - 플라스틱 나일론 (PA)
Net Weight 259.400/mg
열 수 1
방향성 수직
PC 테일길이 0.60mm
PCB 고정위치 No
PCB 유지력 Yes
포장타입 엠보스드 테이프 / 릴
피치 - 결합부 1.25mm
결합제품 오삽입 장치 Yes
PCB 오삽입 장치 Yes
덮개 부분적
End-to-End 연결형 No
사용온도 범위 -40° to +85°C
터미네이션 결합방식 표면실장

전기적 특성
전류 - 접촉 당 최대 출력 1.0A
최대전압 125V

원재료 정보
참고 - 도면번호

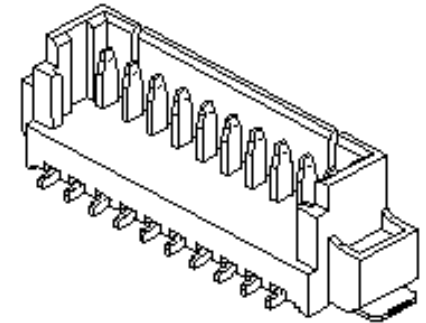

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
Prop65 Compliant
RoHS Phthalates Not Contained

Search Parts in this Series
[53398 Series](#)

Mates With
[PicoBlade Housing 51021](#)
[PicoBlade
Cable Assembly 15134](#)

Packaging Specification
제품규격
도면

SPK-53398-002-001
PS-51021-024-001
SD-53398-032, SD-53398-033-001

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION