

Part Number: [0678038020](#)
 Status: Active
 Overview: [USB Products and Solutions](#)
 Description: USB On-The-Go (OTG) Mini-AB Receptacle, Right-Angle, Surface Mount, with Shell Tabs, Plastic Pegs and Cover Tape, Color Gray, Lead-Free

Documents:

3D 모델 [Packaging Specification PK-67503-001 \(PDF\)](#)
 도면 (PDF) [RoHS 증명서\(PDF\)](#)
 제품규격 PS-67803-001-001 (PDF)


일반적 특성
 적용제품 와이어 대 보드
 부품형태 리셉터클
 전체보기 [USB Products and Solutions](#)
 제품명 USB 2.0, USB OTG (On-The-Go)
 타입 Mini-AB (OTG)
 UPC 822348781034

물리적 특성
 회로수 5
 최대 회로수 5
 색상 - Resin 회색
 암수구분 리셉터클
 결합제품 잠금장치 Yes
 원재료 - 메탈 Copper Alloy
 원재료 - 도금부 금
 원재료 - 도금부 터미네이션 주석
 원재료 - 플라스틱 나일론 (PA)
 Net Weight 0.685/g
 열 수 1
 방향성 직각
 PCB 고정위치 Yes
 PCB 유지력 Yes
 포장타입 엠보스트 테이프 / 릴
 패널마운트 No
 피치 - 결합부 0.80mm
 피치 - 터미널 간격 0.80mm
 최소도금: 결합 0.762µm
 최소 도금: 터미네이션 3.810µm
 결합제품 오삽입 장치 Yes
 PCB 오삽입 장치 Yes
 포트 1
 사용온도 범위 0° to +50°C
 터미네이션 결합방식 표면실장

전기적 특성
 전류 - 접촉 당 최대 출력 1.0A
 차폐형 Yes
 최대전압 30V

납땜 프로세스 정보
 Duration at Max. Process Temperature (seconds) 010
 Lead-freeProcess Capability REFLOW
 Max. Cycles at Max. Process Temperature 001
 Process Temperature max. C 260

원재료 정보

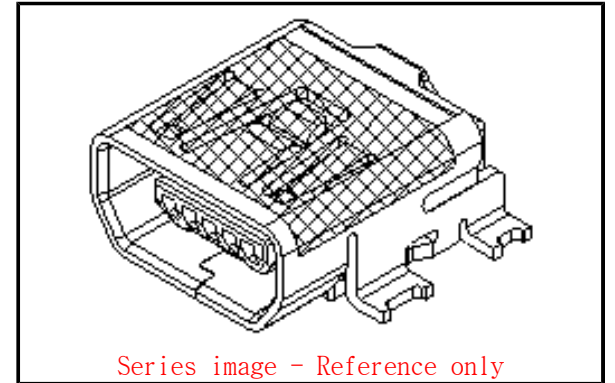

EU ELV
 Not Relevant
 EU RoHS [China RoHS](#)
 Compliant
 REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)
 Halogen-Free
 Status
 Not Low-Halogen
 For more information, please visit
[Contact US](#)
 China ROHS [Green Image](#)
 ELV [Not Relevant](#)
 RoHS Phthalates [Not Contained](#)

Search Parts in this Series
[67803 Series](#)

Mates With
 USB OTG mini-A Plug, USB OTG mini-B
 Plug, [88753 Cable Assembly](#)

참고 - 도면번호
Packaging Specification
제품규격
도면

PK-67503-001
PS-67803-001-001
SD-67803-002

This document was generated on 09/28/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION