

Part Number: [0743204000](#)
Status: Active
Overview: [MicroCross DVI Connectors and Cable Assemblies](#)
Description: MicroCross DVI-D Digital Visual Interface, PCB Receptacle, Panel Mount, Polyester (PCT), Through Hole, 2.34mm PC Tail Length, Right-Angle, 0.76µm Gold (Au), Lead-Free, Screw Hole, 24 Circuits

Documents:

3D 모델	Packaging Specification PK-74320-010 (PDF)
도면 (PDF)	Test Summary TS-74320-001 (PDF)
제품규격 PS-74320-001 (PDF)	RoHS 증명서(PDF)

Agency Certification

UL E29179

일반적 특성

적용제품	와이어 대 보드
설명	DDWG (Digital Display Working Group) Standard
부품형태	리셉터클
Electrical Model	Yes
전체보기	MicroCross DVI Connectors and Cable Assemblies
제품명	MicroCross DVI
타입	N/A
UPC	800754009980

물리적 특성

부트색상	N/A
회로수	24
최대 회로수	24
색상 - Resin	Natural
내구성(최대 메이팅 사이클)	100
난연성	94V-0
암수구분	리셉터클

Keying to Mating Part

결합제품 잠금장치	Yes
원재료 - 메탈	Copper Alloy
원재료 - 도금부	금
원재료 - 도금부 터미네이션	주석

Net Weight 6.630/g

열 수 3

방향성 직각

PC 테일길이 2.34mm

PCB 고정위치 Yes

PCB 유지력 Yes

포장타입 트레이

패널마운트 Yes

피치 - 결합부 1.90mm

피치 - 터미널 간격 1.90mm

최소도금: 결합 0.762µm

최소 도금: 터미네이션 2.540µm

결합제품 오삽입 장치 Yes

PCB 오삽입 장치 Yes


포트 1

표면실장호환성 (SMC) No

사용온도 범위 -20° to +85°C

터미네이션 결합방식 스루홀

방수/방진 No

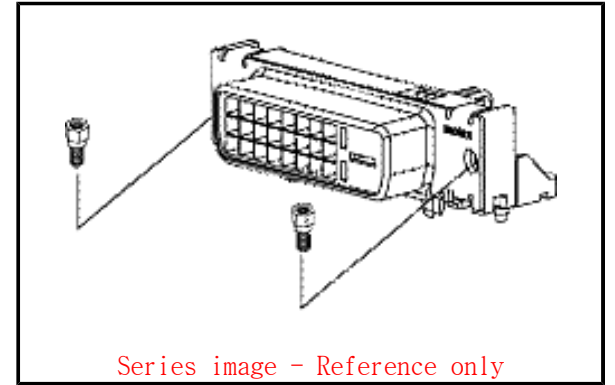

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[74320 Series](#)

Mates With
[88744](#) , [74323](#)

Use With
Hex Screw Kit [71781-1000](#) or [71781-2000](#)

와이어 사이즈 (AWG)	N/A
전기적 특성	
전류 - 접촉 당 최대 출력	3.0A
패널 그라운드	Yes
차폐형태	폴 실드
차폐형	Yes
최대전압	40V AC (RMS)
납땜 프로세스 정보	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260
원재료 정보	
참고 - 도면번호	
Electrical Model Document	EE-74320-001
Packaging Specification	PK-74320-010
제품규격	PS-74320-001
S-Parameter Model	SP-74320-001
도면	SD-74320-003-000
Test Summary	TS-74320-001

This document was generated on 08/16/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION