

Part Number: [0874390600](#)
Status: Active
Overview: [Pico-SPOX Wire-to-Board Connector System](#)
Description: 1.50mm Pitch Pico-SPOX Wire-to-Board Housing, 6 Circuits, Off-White Housing

Documents:

3D 모델	제품규격 PS-87437-001-001 (PDF)
도면 (PDF)	Packaging Specification SPK-87439-001-001 (PDF)
제품규격 2027050000-000 (PDF)	RoHS 증명서(PDF)
제품규격 PS-78047-001-001 (PDF)	Product Literature (PDF)

Agency Certification

CSA	LR19980
UL	E29179

일반적 특성

적용제품	Signal, 와이어 대 보드
전체보기	Pico-SPOX Wire-to-Board Connector System
Product Literature Order No	USA-235
제품명	Pico-SPOX
UPC	800753537248

물리적 특성

최대 회로수	6
색상 - Resin	Natural
난연성	94V-0
암수구분	리셉터클
Glow-Wire Capable	No
결합제품 잠금장치	Yes
원재료 - 플라스틱	나일론 (PA)
Net Weight	80.000/mg
열 수	1
포장타입	백 (Bag)
패널마운트	No
피치 - 결합부	1.50mm
결합제품 오삽입 장치	Yes
End-to-End 연결형	No
사용온도 범위	-55° to +105°C


전기적 특성

전류 - 접촉 당 최대 출력	2.5A
-----------------	------

원재료 정보

참고 - 도면번호

Packaging Specification	SPK-87439-001-001
제품규격	2027050000-000, PS-78047-001-001, PS-87437-001-001
도면	SD-87439-***0

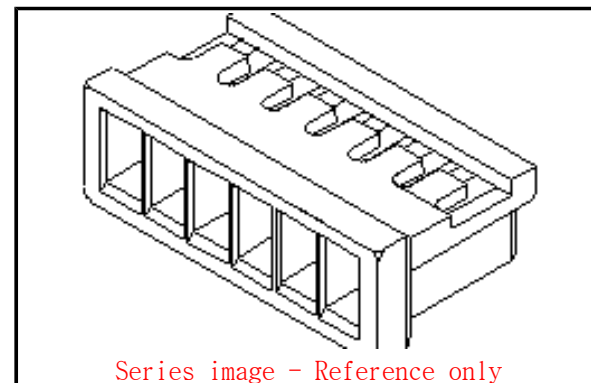

EU ELV
Compliant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
Contact US

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[87439 Series](#)

Mates With
Pico-SPOX Wire-to-Board Header [87437](#) ,
[87438](#)

Use With
[87421](#) Pico-SPOX Crimp Terminal