

Part Number: [0901420040](#)
Status: Active
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Crimp Housing Dual Row, 40 Circuits, Black

Documents:

[3D 모델](#) [Packaging Specification PK-90142-0001 \(PDF\)](#)
[도면 \(PDF\)](#) [RoHS 증명서\(PDF\)](#)
[제품규격 PS-99020-0001-001 \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

일반적 특성

적용제품 Signal, 와이어 대 보드
전체보기 [C-Grid III Interconnects](#)
제품명 C-Grid III
UPC 800753656239

물리적 특성

분리형 No
최대 회로수 40
색상 - Resin Black
난연성 94V-0
암수구분 리셉터클
Glow-Wire Capable No
Keying to Mating Part 없음
결합제품 잠금장치 Yes
원재료 - 플라스틱 PPO
Net Weight 2.716/g
열 수 2
포장타입 백 (Bag)
패널마운트 No
피치 - 결합부 2.54mm
피치 - 터미널 간격 2.54mm
결합제품 오삽입 장치 Yes
포트 0
End-to-End 연결형 No
사용온도 범위 -55° to +105°C


납땜 프로세스 정보

Lead-freeProcess Capability N/A

원재료 정보

참고 - 도면번호

Packaging Specification PK-90142-0001
제품규격 PS-99020-0001-001
도면 SD-90142

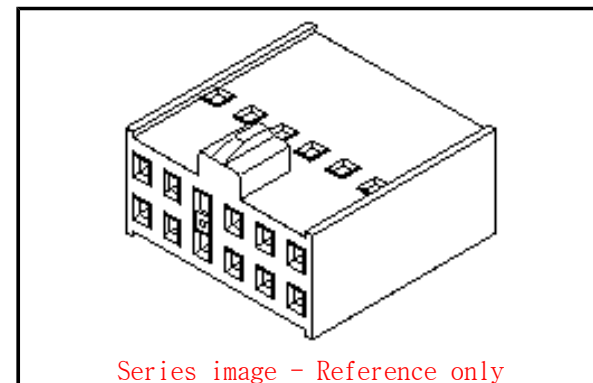

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
Contact US

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[90142](#) Series

Mates With
C-Grid III Header, Dual Row [90122](#) ,
[90130](#) , [90131](#)

Use With
C-Grid III Crimp Terminal [90119](#)