

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0733910070](#)
Status: **Active**
Overview: [SMA RF Connectors](#)
Description: 50 Ohms, SMA PCB Jack Receptacle, Vertical, with Standoffs, 80 Pieces Per Tray

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	RF/Coax Connectors
Series	73391
Overview	SMA RF Connectors
Product Name	SMA
Style	PCB
Type	Subminiature
UPC	800753926158
Wire/Cable Type	N/A

Physical

Gender	Jack
Keying to Mating Part	None
Net Weight	1.474/g
Orientation	Straight
PCB Mounting	Through Hole
PCB Thickness - Recommended	3.00mm
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No

Electrical

Frequency	18 GHz
Impedance	50Ω


Solder Process Data

Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-73391-007
---------------	--------------

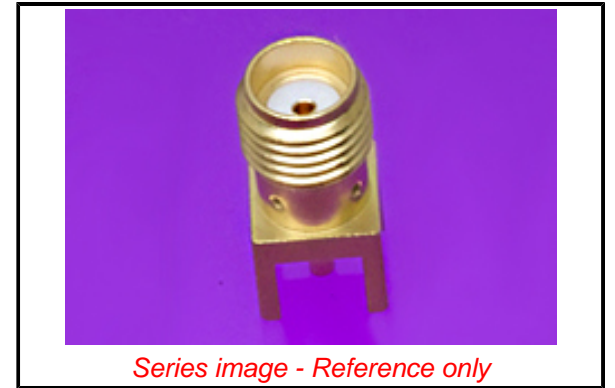

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Prop65

PropRisk

PropRisk

PropRisk

PropSub

RoHS Phthalates

50 Image

Not Relevant

Duty-To-Declare

Cancer

Developmental toxicity

Reproductive toxicity

Lead and its compounds

Not Contained

Search Parts in this Series

[73391](#) Series