


■ ELECTRICAL SPECIFICATION


SPECIFICATIONS	SPECIFICATIONS	UNIT
Frequency Range	2400 ~ 2500	MHz
Gain	9	dBi
VSWR, max	2.0	-
Polarization	Vertical	-
Return Loss	-10	dBi
Impedance	50	$\Omega$
Connector	N Male	-
Operating Temperature Range	-40~ +55	$^{\circ}\text{C}$
Rated Wind Velocity	60	m/s
Radome Material	Fiberglass	-
Color	Gray	-



■ DIMENSIONS

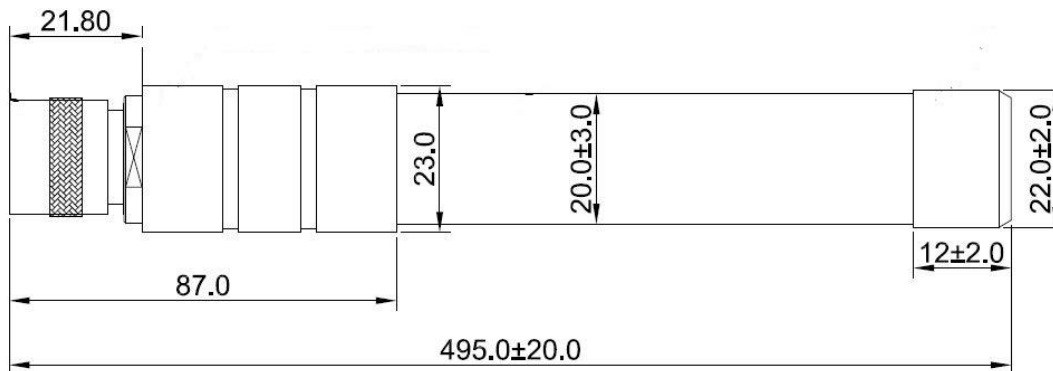

#### FREQUENCY CHARACTERISTICS

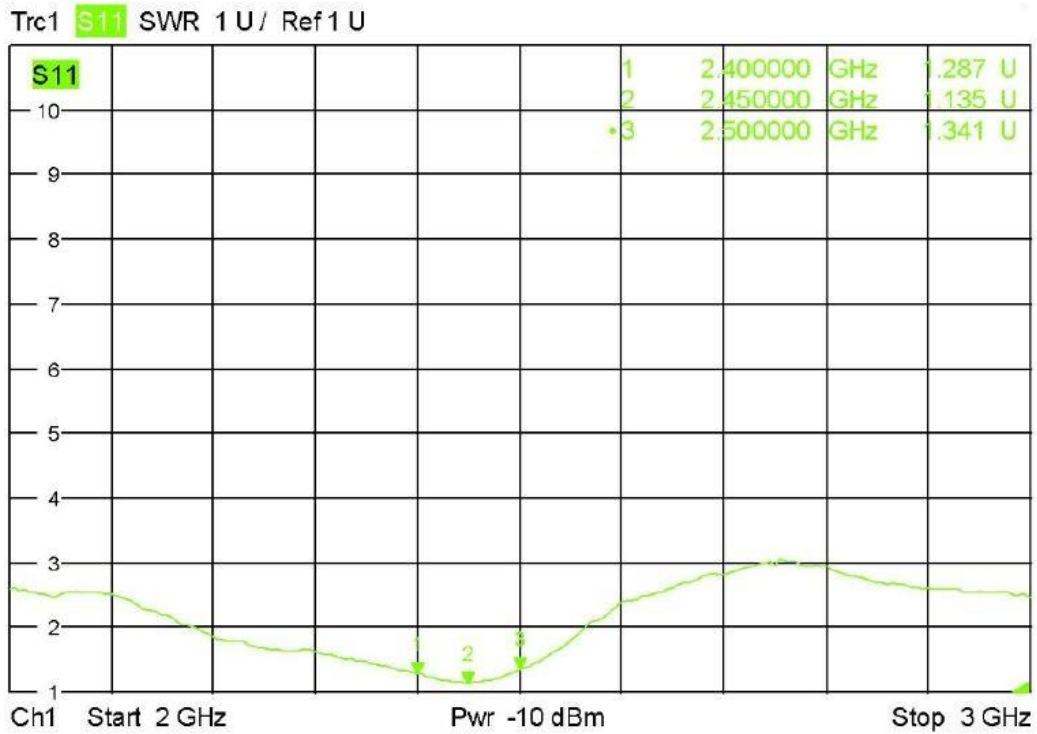

June 2017