


ELECTRICAL SPECIFICATION

SPECIFICATIONS	SPECIFICATIONS	UNIT
Frequency Range	2400 ~ 2483	MHz
Bandwidth	83	MHz
Nominal Impedance	50	Ω
VSWR, max	1.5	-
Polarization	Vertical	-
Gain	4.15	dBi
Power, max	30	W
Length	110	mm
Weight	25	g
Connector	SMA Male	-




TEST DATA


IMPEDANCE

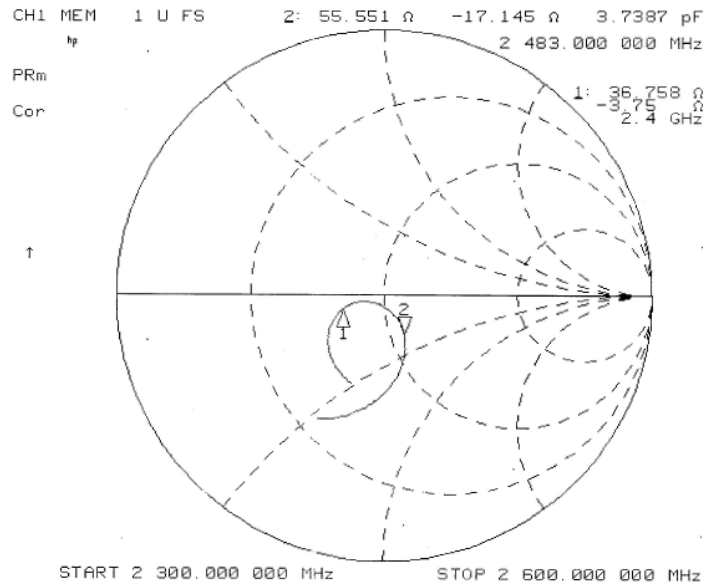

PATTERN AT 2400 MHz

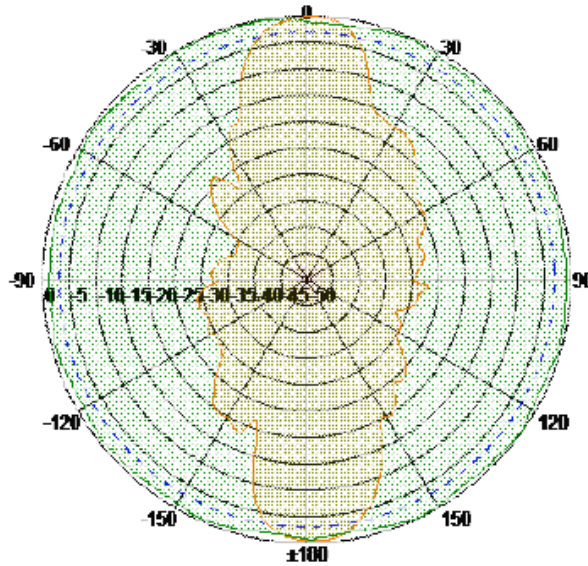

PATTERN AT 2500 MHz

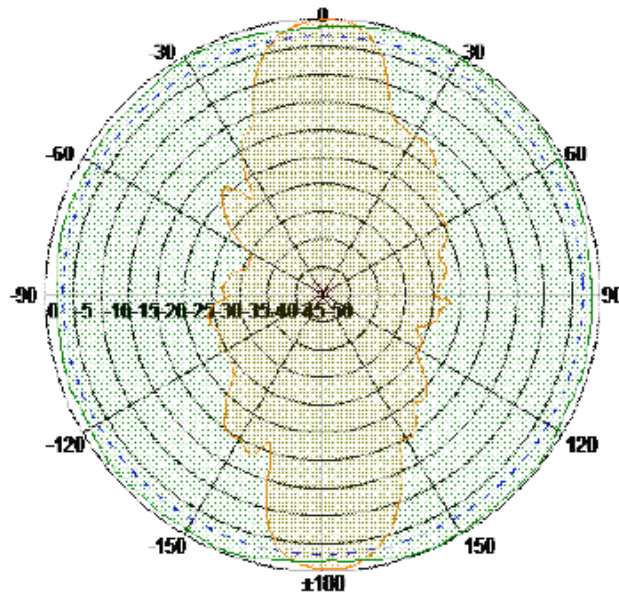

■ APPROVAL

RALTRON	
DRAWN BY:	CP, February 15, 2016
APPROVED BY:	CP, February 15, 2016
REVISION:	A, Initial Release