

ABI-047-RC IP54 SOUNDER

SOUNDERS & BUZZERS

Specifications


	ABI-047-RC
Rated voltage	10VDC
Operating voltage	5~25VDC
Rated current*	≤25mA
Sound output at 10cm*	≥100dB
Coil resistance	2900Ω±500Hz
Operating temperature	-20~+65°C
Storage temperature	-40~+85°C
Weight	20g

*Value applying at rated voltage (DC)

Features

- ROHS compliant
- IP54 rated sounder
- With internal drive circuit
- Housing material: Noryl
- Wire leads: UL1007 – AWG22

All data at 25°C unless otherwise specified

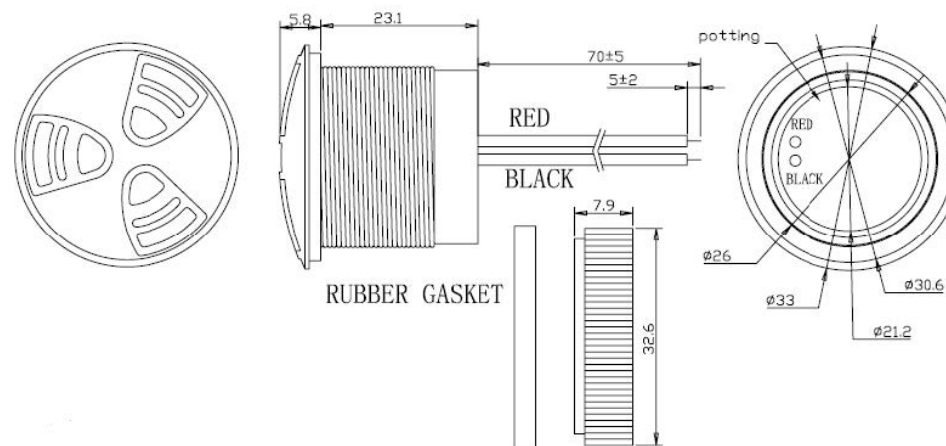

Dimensions Unit: mm Tolerance: ±0.5mm