

PROFESSIONAL

Heat Tools | Lighting Controls

SEARCH: 

About STEINEL

Products


Resources

Sales

Tech Support

Press

PRODUCTS

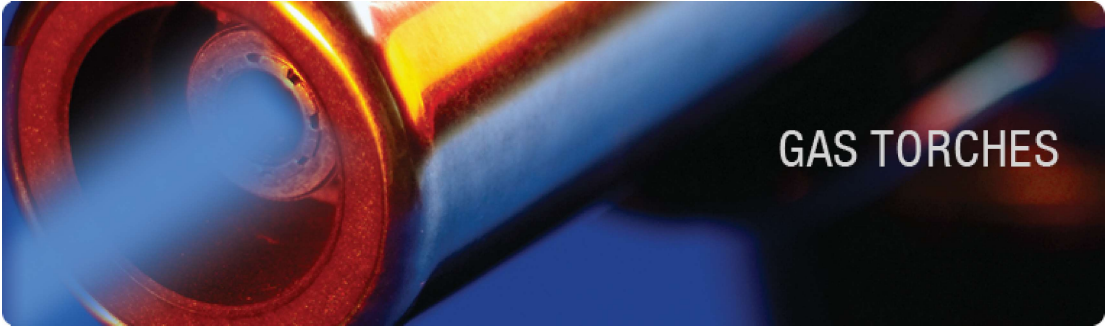

INDUSTRIAL HEAT GUNS

PROFESSIONAL HEAT GUNS

PRECISION HOT AIR TOOLS

PROFESSIONAL HEAT
BLOWERS

GENERAL PURPOSE HEAT
GUNS

GAS TORCHES

UBK

TT 270

TT 175

SPECIFICATIONS

ACCESSORIES

KITS

APPLICATIONS

TT 151

TT 30

TS 600 AND TS 600 K

TS 550 AND TS 550 K

TS 500 AND TS 500 K

TH 310

HOT-MELT ADHESIVE SYSTEMS

home > heat tools > products > gas torches > tt 175 > specifications >

SPECIFICATIONS

Item No.	71175
Temperature	2400°F (1316°C)
Fuel Capacity	60ml refillable fuel tank
Operating Time	120 min continuous use
Fuel Type	Standard butane fuel
Ignition	Water proof piezo electronic system
Nozzle Diameter	0.78" (19.8 mm)
Dimensions	5.25" x 4.00" x 1.50"
Net Weight	0.59 lb (9.44 oz)
Single Sell Pack	Dimensions: 7.40" x 5.50" x 1.75" Weight: 0.78 lb (12.48 oz)
Warranty	One year limited

SPECIFICATIONS

ACCESSORIES

KITS

APPLICATIONS

Customer Service until 5 PM
(800) 852-4343 | sales@steinel.net

Follow Us: