

# PRODUCT FAMILY DATASHEET

## SURFACE CIRCULAR 400

Wall and ceiling luminaire with IP44



---

### AREAS OF APPLICATION

- Corridors
- Stairways
- Bathrooms
- Foyers

---

### PRODUCT BENEFITS

- High luminous efficacy
- Energy savings of up to 55 % compared to luminaires that use CFL
- Easy and quick installation
- Very homogenous light
- Clear cover protects the reflector against dust and contact
- 3 years guarantee

---

### PRODUCT FEATURES



- Beam angle: 120°
- Type of protection: IP44
- Impact resistance: IK03
- Metal housing, PMMA cover
- Ambient temperature in operation: -20...+40 °C




TECHNICAL DATA

Product description	Electrical data			Photometrical data			Light technical data	Dimensions & weight			Colors & materials
	Nominal wattage	Nominal voltage	Mains frequency	Luminous flux	Light color (designation)	Color rendering index Ra	Beam angle	Diameter	Height	Product weight	Body material
SF CIRCULAR 400 24 W 3000 K WT	24.00 W	220...240 V	50/60 Hz	1920 lm	Warm White	>80	120 °	400.0 mm	120.0 mm	708.00 g	Steel
SF CIRCULAR 400 24 W 4000 K WT	24.00 W	220...240 V	50/60 Hz	1920 lm	Cool White	>80	120 °	400.0 mm	120.0 mm	708.00 g	Steel

Product description	Product color	Temperatures & operating conditions	Capabilities		Certificates & standards	
		Ambient temperature range	Dimmable	Type of connection	Protection class	Type of protection
SF CIRCULAR 400 24 W 3000 K WT	White	-20...40 °C	No	Terminal, 3-pin	I	IP44
SF CIRCULAR 400 24 W 4000 K WT	White	-20...40 °C	No	Terminal, 3-pin	I	IP44

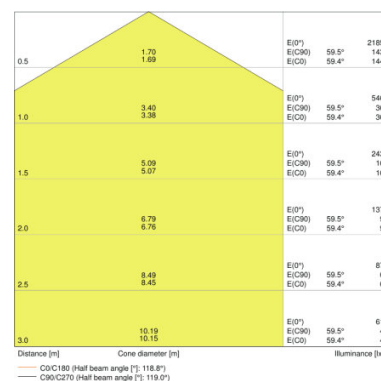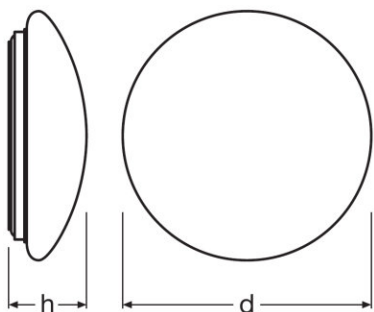

SF CIRCULAR 400 24 W 3000 K WT, SF CIRCULAR 400 24 W 4000 K WT

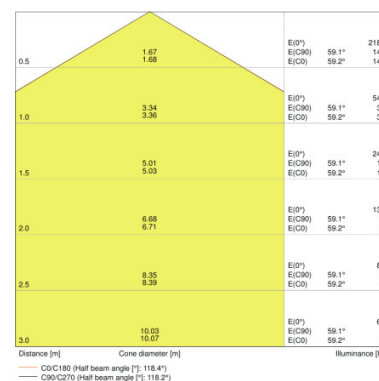

SF CIRCULAR 400 24 W 3000 K WT

SF CIRCULAR 400 24 W 4000 K WT

---

**EQUIPMENT / ACCESSORIES**

- Replacement cover optional available

---

**APPLICATION ADVICE**

For more detailed application information and graphics please see product datasheet.

---

**LOGISTICAL DATA**

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4058075080058	SF CIRCULAR 400 24 W 3000 K WT	Shipping carton box 5	660 mm x 460 mm x 460 mm	139.66 dm <sup>3</sup>	6060.00 g
4058075080072	SF CIRCULAR 400 24 W 4000 K WT	Shipping carton box 5	660 mm x 460 mm x 460 mm	139.66 dm <sup>3</sup>	6160.00 g

- The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

**REFERENCES / LINKS**

For Guarantee see

- ▶ [www.ledvance.com/guarantee](http://www.ledvance.com/guarantee)

---

**DISCLAIMER**

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.