

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190360008
Status: Active
Overview: Snap Plugs and Receptacles
Description: Avikrimp Snap Plug, for 14-16 AWG Wire, Box, 22.78mm Length

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E152602

General

Product Family Quick Disconnects
Series 19036
Comments Extruded Nylon Insulation
Crimp Quality Equipment Yes
Insulated Partial
Overview Snap Plugs and Receptacles
Product Name Avikrimp
Type Snap Plug
UPC 800753048225

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Male
Glow-Wire Capable No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.506/g
Orientation Straight
Packaging Type Bag
Tab Thickness N/A
Tab Width N/A
Wire Insulation Diameter 4.30mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical


Voltage - Maximum N/A

Material Info

Engineering Number B-889

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19036-001

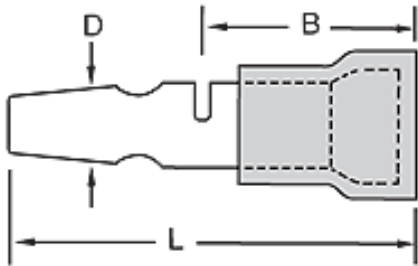

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Missing Compliance Data
RoHS Phthalates	Not Contained

Search Parts in this Series

19036 Series