


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190700123**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp Ring Tongue Terminal for 10-12 AWG Wire

Documents:

3D Model	Product Specification 194130108-000 (PDF)
Drawing (PDF)	Product Specification PS-19902-009-001 (PDF)
Product Specification 194130096-000 (PDF)	Product Specification PS-19902-011-001 (PDF)
Product Specification 194130104-000 (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification 194130107-000 (PDF)	RoHS Certificate of Compliance (PDF)

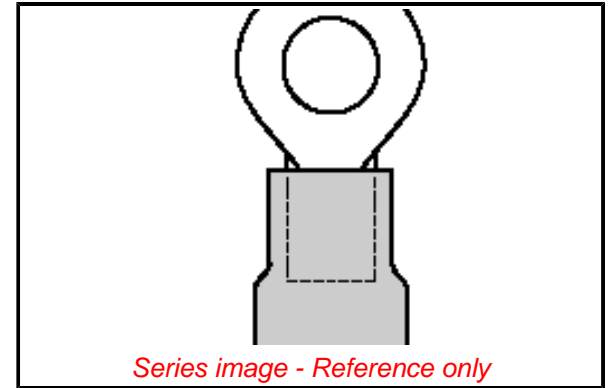

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	<u>19070</u>
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<u>Solderless Terminals</u>
Product Name	InsulKrimp
Type	Ring
UPC	800753069701

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.869/g
Packaging Type	Bag
Stud Size	10 (M5)
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12
Wire Size mm ²	3.30-5.00

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	C-228-10X
--------------------	-----------

Reference - Drawing Numbers

Product Specification	194130096-000, 194130104-000, 194130107-000, 194130108-000, PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19070-007

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19070 Series