

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191290053
Status: Active
Overview: Solderless Terminals
Description: Krimptite Block Spade Terminal for 18-22 AWG Wire

Documents:
3D Model Product Specification PS-19902-013-001 (PDF)
Drawing (PDF) RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19129
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Krimptite
Type Spade Block
UPC 800755084047

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.371/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 3-4 (M2.6)
Termination Interface: Style Crimp or Compression
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Material Info
Engineering Number AA-1109-04

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing AACD10302

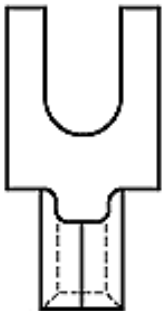

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)
Halogen-Free
Status
Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19129](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION