

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191390016
Status: Active
Overview: Solderless Terminals
Description: Avikrimp Block Spade Terminal for 18-22 AWG Wire, Stud Size 4 (M2.6)

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series 19139
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Avikrimp
Type Spade Block
UPC 800753102606

Physical
Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 1.217/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 4 (M2.6)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.56mm
Wire Size AWG 18, 20, 22
Wire Size mm² 0.25-1.50

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number AA-838-04

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19139-001

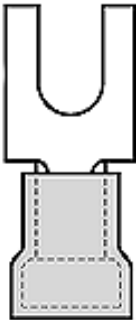

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Not Relevant ELV Not Relevant Prop65 Compliant RoHS Phthalates Not Contained
---	---

Search Parts in this Series
[19139 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION