

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0347960401](#)
Status: **Active**
Overview: MX150™ Unsealed Connector System
Description: MX150 Cable Unsealed Female Connector, Single Row, 4 Circuits, Polarization A, Black

Documents:

[3D Model](#) [Packaging Specification PK-31301-695-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	34796
Application	Power, Wire-to-Wire
Overview	<u>MX150™ Unsealed Connector System</u>
Polarization	A
Product Name	MX150 Unsealed
UPC	884982969742

Physical

Circuits (maximum)	4
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	2.810/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C


Electrical

Current - Maximum per Contact	22.0A
-------------------------------	-------

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-31301-695-001
Sales Drawing	SD-34796-001

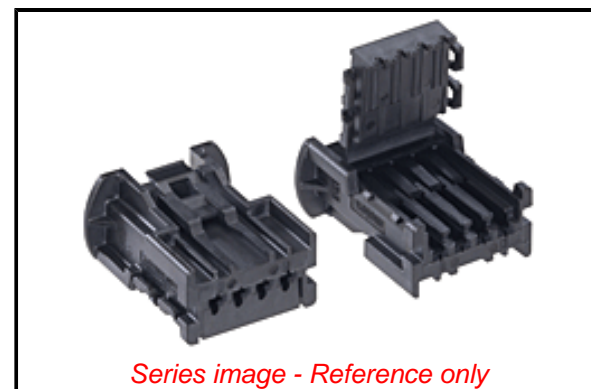

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Compliant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[34796](#) Series

Mates With

[34797](#) 3.50mm Pitch MX150 Cable Unsealed Male

Use With

MX150 Female Terminal [33012-2021](#) ,
[33012-2022](#) , [33012-2023](#) , [33012-3021](#) ,
[33012-3022](#) , [33012-3023](#)