

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395200007

Status: **Active**

Overview: Eurostyle Terminal Blocks

Description: 5.00mm Pitch Eurostyle Horizontal Plug, 7 Circuits

Documents:

3D Model

Product Specification PS-39500-001-001 (PDF)

Drawing (PDF)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	<u>39520</u>
Application	N/A
Component Type	Plug
Overview	<u>Eurostyle Terminal Blocks</u>
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350466370

Physical

Circuits (Loaded)	7
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	5.00mm
Pitch - Termination Interface	5.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm²	0.13-3.31


Electrical

Current - Maximum per Contact	18.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Product Specification	PS-39500-001-001
Sales Drawing	SD-39520-001

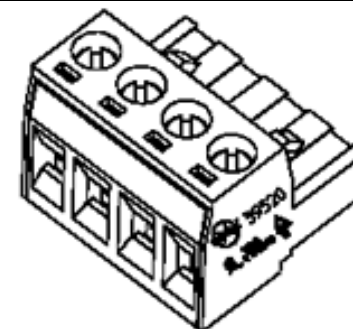

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
ED/61/2018 (27 June
2018)

Lead

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
Prop65	Duty-To-Declare
PropRisk	Cancer
PropRisk	Developmental toxicity
PropRisk	Reproductive toxicity
PropSub	Lead and its compounds
RoHS Phthalates	Not Contained

Search Parts in this Series

39520 Series

Mates With

39521 Vertical PCB Header, 39522
Horizontal PCB Header, Most 5.00mm Pitch
Industry Standard PCB Headers, 39528
Dual Level PCB Header, Open Ends

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION