

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0430201401

Status:


Active

Overview:

Micro-Fit 3.0 Connector System Product Family

Description:

Micro-Fit 3.0 Plug Housing, Dual Row, 14 Circuits, UL 94V-0, Low-Halogen, Black

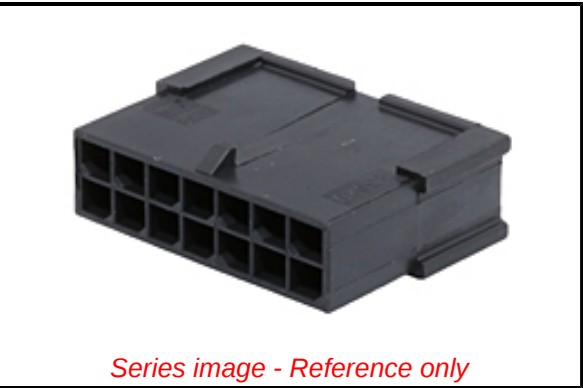

Documents:	
Drawing (PDF)	Product Specification TS-46235-001-001 (PDF)
3D Model	Packaging Specification PK-43020-001-001 (PDF)
Product Specification PS-43045 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-43045-001 (PDF)	Product Literature (PDF)
Product Specification TS-43045-001-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	43020
Application	Power, Wire-to-Wire
Overview	Micro-Fit 3.0 Connector System Product Family
Product Literature Order No	987650-5984
Product Name	Micro-Fit 3.0
UPC	800754383639
Physical	
Circuits (maximum)	14
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.518/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-43020-001-001
Product Specification	PS-43045, PS-43045-001, TS-43045-001-001, TS-46235-001-001
Sales Drawing	SDA-43020-****

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
43020 Series

Mates With
Micro-Fit 3.0 Receptacle Housings 43025

Use With
Micro-Fit 3.0 Male Crimp Terminals 43031

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION