

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0513532000

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 20 Circuits, White

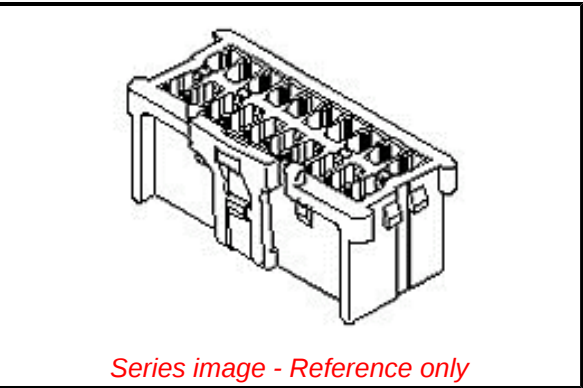

Documents:

3D Model

Packaging Specification SPK-51353-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-51353-003-001 (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	51353
Application	Signal, Wire-to-Board
Overview	MicroClasp Wire-to-Board System
Product Name	MicroClasp
UPC	756054235829
Physical	
Circuits (maximum)	20
Color - Resin	White
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	958.000/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-25° to +85°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-51353-001-001
Product Specification	PS-51353-003-001
Sales Drawing	SD-51353-002

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Prop65

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

51353 Series

Mates With

55917 Vertical Header with Kinked PC Tails, 55959 Right Angle Header, 501844 Vertical Header

Use With

56134 Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION