

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0513533600**
Status: **Active**
Overview: MicroClasp Wire-to-Board System
Description: 2.00mm Pitch MicroClasp Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 36 Circuits, White

Documents:

[3D Model](#) [Packaging Specification SPK-51353-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-51353-003-001 \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
 Series 51353
 Application Signal, Wire-to-Board
 Overview MicroClasp Wire-to-Board System
 Product Name MicroClasp
 UPC 800756611167


Physical

Circuits (maximum) 36
 Color - Resin White
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Capable No
 Lock to Mating Part Yes
 Material - Resin Nylon
 Net Weight 1583.000/mg
 Number of Rows 2
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.00mm
 Stackable No
 Temperature Range - Operating -25° to +85°C

Material Info

Reference - Drawing Numbers

Packaging Specification SPK-51353-001-001
 Product Specification PS-51353-003-001
 Sales Drawing SD-51353-002

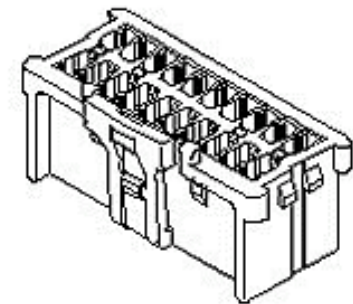

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Prop65

RoHS Phthalates

Green Image

Not Relevant

Compliant

Not Contained

Search Parts in this Series

51353 Series

Mates With

55917 Vertical Header with Kinked PC Tails, 55959 Right Angle Header, 501844 Vertical Header

Use With

56134 Terminal