

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0673298000](#)  
**Status:** **Active**  
**Overview:** [USB Products and Solutions](#)  
**Description:** Universal Serial Bus (USB) Shielded I/O Receptacle, Type A, Single Upright Right-Angle, Solder Tail Length 2.00mm, Kinked Pins, PCB Thickness 1.20mm and 1.60mm, Gold (Au) Flash, Lead-Free

**Documents:**

[3D Model](#) [Packaging Specification PK-67329-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-89485 \(PDF\)](#)

**Agency Certification**

UL E29179

**General**


Product Family I/O Connectors  
 Series [67329](#)  
 Application Wire-to-Board  
 Comments Standard Mount Type  
 Component Type Receptacle  
 Overview [USB Products and Solutions](#)  
 Product Name USB 2.0  
 Type A  
 UPC 822350416887

**Physical**

Circuits (Loaded) 4  
 Circuits (maximum) 4  
 Flammability 94V-0  
 Gender Female  
 Lock to Mating Part Yes  
 Material - Plating Mating Gold  
 Material - Plating Termination Tin  
 Net Weight 2.025/g  
 Number of Rows 4  
 Orientation Upright  
 PC Tail Length 2.00mm  
 PCB Locator Yes  
 PCB Retention Yes  
 PCB Thickness - Recommended 1.60mm  
 Packaging Type Tray  
 Panel Mount No  
 Pitch - Mating Interface N/A  
 Pitch - Termination Interface 1.40mm  
 Plating min - Mating 0.102µm  
 Plating min - Termination 2.540µm  
 Polarized to Mating Part Yes  
 Polarized to PCB Yes  
 Ports 1  
 Surface Mount Compatible (SMC) Yes  
 Termination Interface: Style Through Hole  
 Waterproof / Dustproof No

**Electrical**

Current - Maximum per Contact 1.0A  
 Shield Type Full Shield

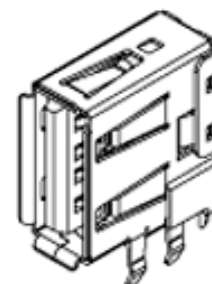

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/61/2018 (27 June  
 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[67329 Series](#)

**Mates With**

USB Type A Plug

Shielded

Yes

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification

PK-67329-001-001

Product Specification

PS-89485

Sales Drawing

SD-67329-801

This document was generated on 10/11/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**