

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0872630623](#)
Status: **Active**
Overview: [Milli-Grid Connector System](#)
Description: 2.00mm Pitch Milli-Grid Receptacle, Surface Mount, Bottom Entry, 0.38µm Gold (Au)
Selective, 6 Circuits, without Pick-and-Place Cap, Tube, Lead-Free

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Packaging Specification PK-87263-0001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)
[Product Literature \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family PCB Receptacles
Series [87263](#)
Application Board-to-Board, Signal
Overview [Milli-Grid Connector System](#)
Product Literature Order No 987650-1991
Product Name Milli-Grid
UPC 822348478729

Physical


Circuits (Loaded) 6
Circuits (maximum) 6
Color - Resin Black
Durability (mating cycles max) 25
Flammability 94V-0
Glow-Wire Capable No
Lock to Mating Part None
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 0.115/g
Number of Rows 2
Orientation Bottom Entry
PCB Locator Yes
PCB Retention None
Packaging Type Tube
Pitch - Mating Interface 2.00mm
Pitch - Termination Interface 2.00mm
Plating min - Mating 0.381µm
Polarized to Mating Part No
Polarized to PCB Yes
Temperature Range - Operating -55° to +105°C
Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 1.0A
Voltage - Maximum 125V

Solder Process Data

Duration at Max. Process Temperature (seconds) 014
Lead-freeProcess Capability REFLOW
Max. Cycles at Max. Process Temperature 001
Process Temperature max. C 265

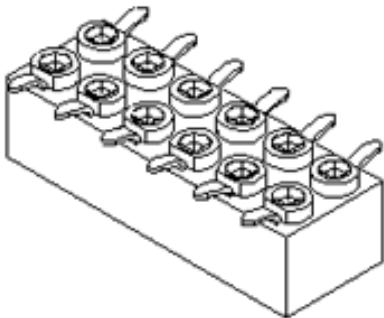

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[87263](#) Series

Mates With

[87759](#) Vertical, Surface Mount, Stackable
PCB Headers, [87760](#) Right Angle, Through
Hole, Stackable PCB Headers, [87758](#)
Vertical, Through Hole, Stackable PCB
Headers

Material Info

Reference - Drawing Numbers

Packaging Specification
Sales Drawing

PK-87263-0001-001
SD-87263-**2*

This document was generated on 10/11/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION