

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0887328600**
Status: **Active**
Overview: USB Products and Solutions
Description: USB On-The-Go (OTG) Shielded I/O Cable Assembly, USB A-to-Mini B, USB 2.0, 1.0m Length, White

Documents:

[Drawing \(PDF\)](#)

[Packaging Specification PK-88732-8401 \(PDF\)](#)

[Packaging Specification PK-88740-012 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	88740
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Mini-B
Overview	<u>USB Products and Solutions</u>
Product Name	USB
UPC	800756178516

Physical

Cable Length	1.0m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	38.900/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm, 2.50mm
Plating min - Mating	0.762µm
Plating min - Termination	4.064µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round


Electrical

Current - Maximum per Contact	1.0A
Shielded	Yes
Voltage - Maximum	30V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-88732-8401, PK-88740-012
Sales Drawing	SD-887328500

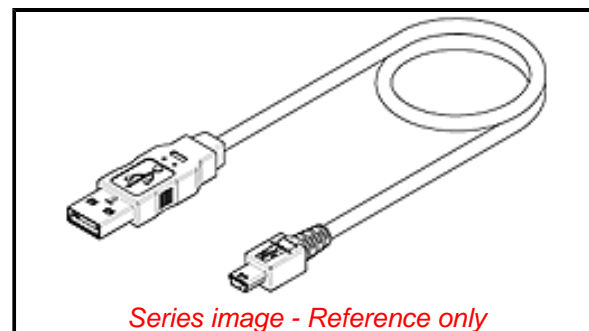

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

88740 Series

Mates With

USB On-The-Go (OTG) Mini-B Receptacle
54819 , 48242 , 500075 , 67503. Universal
Serial Bus Shielded Receptacle Type
A 67329 , 67226 , 67230 , 89485.
54366 Universal Serial Bus Shielded I/O
Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION