
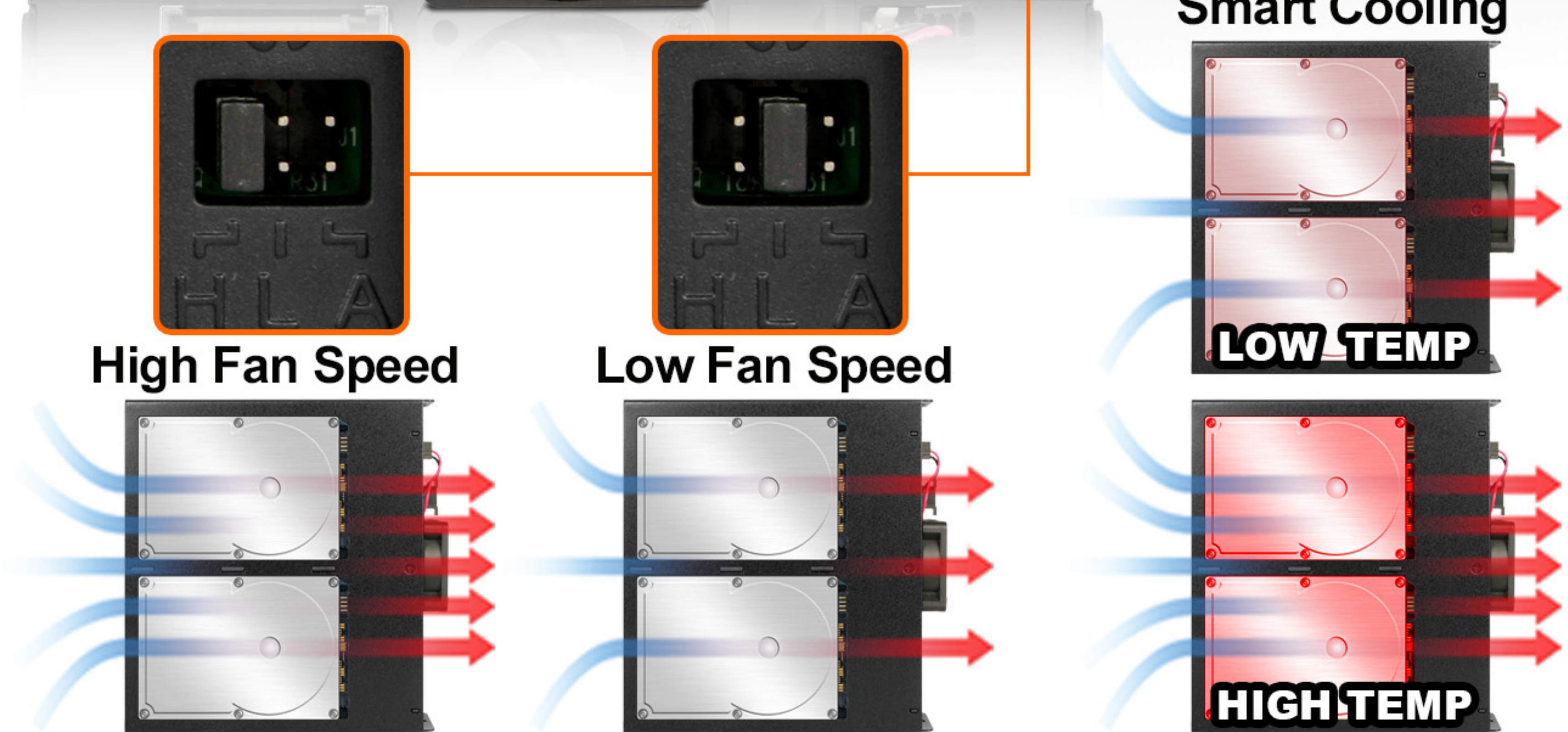
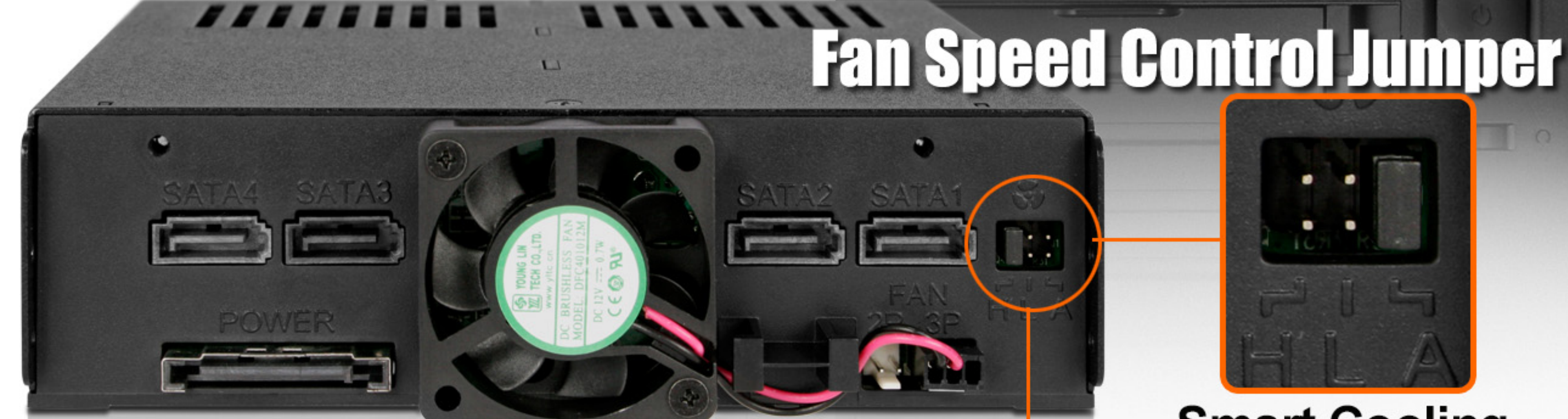
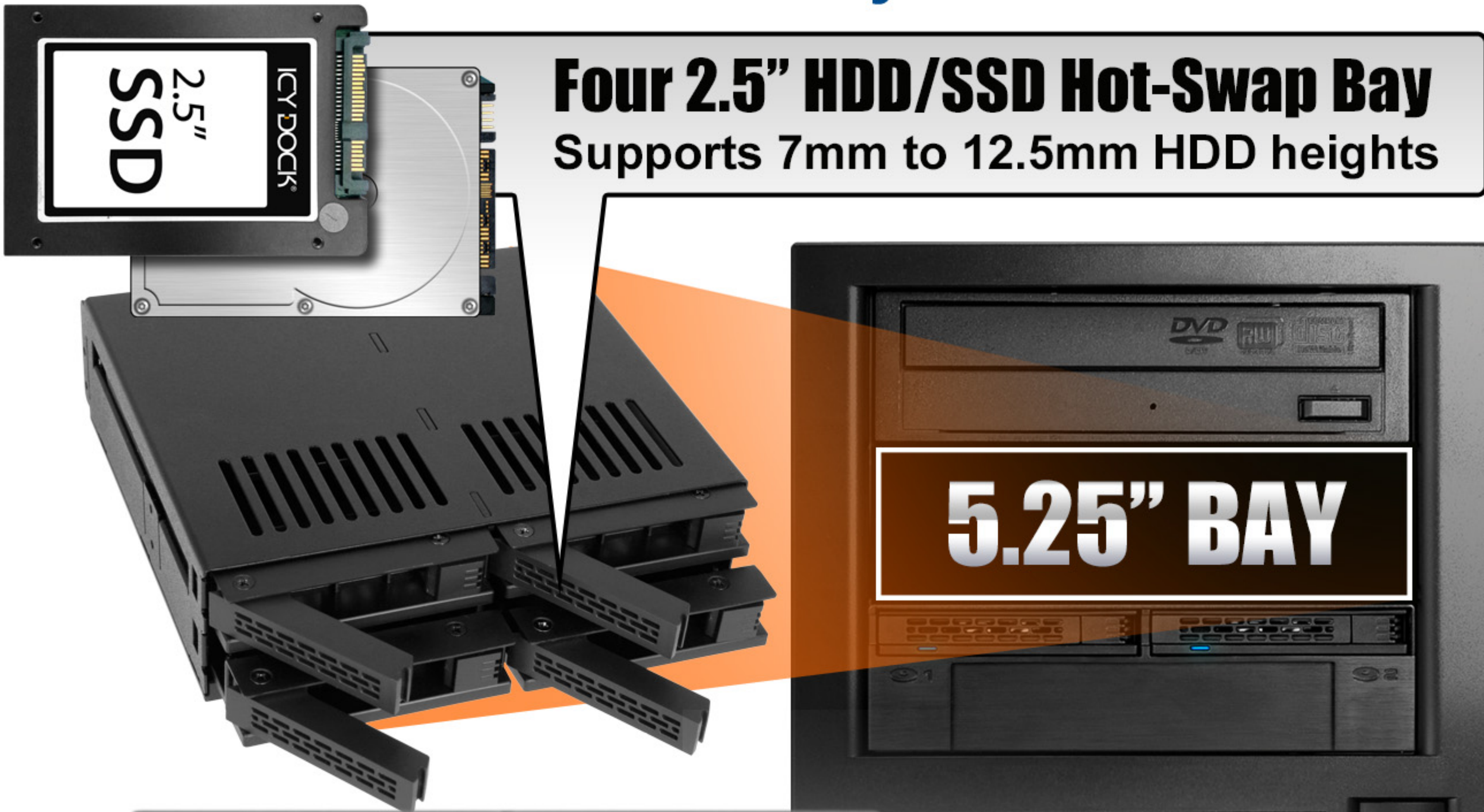


ExpressCage MB324SP-B

4 x 2.5" SATA 6Gbps/SAS HDD/SSD
Mobile Rack / Cage in 1 x 5.25" bay

ICY DOCK®
www.icydock.com

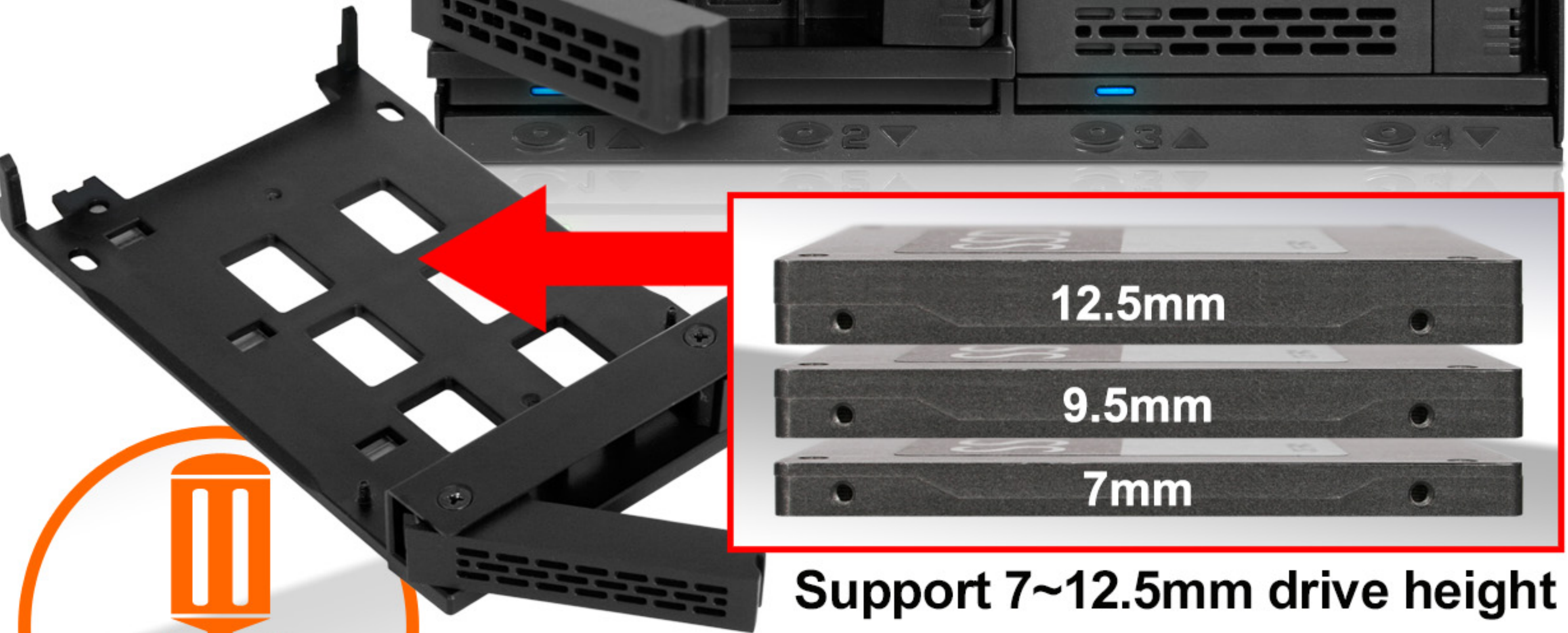

ExpressCage MB324SP-B Features & Specs

- Supports up to 4 x 2.5" SATA/SAS HDD/SSD into a single 5.25" bay
- Support SATA 6Gbps or SAS single channel (requires SAS host)
- Hot-swappable bays for quick drive installation
- Accommodates 2.5" drives with 7mm, 9mm & 12.5mm Height
- Active Power Technology (APT) - only powers up if there is drive installed in the drive bay
- Removable ExpressTray system for tool-less, easy installation
- Optional bottom mounted screw holes for increased stability
- Blue indicator LED provided for each bay
- 40mm upgradeable fan for drive cooling
- 2 pin and 3 pin fan headers to support many aftermarket fan upgrades
- Single 15pin SATA power connection powers all 4 drives
- Locking latch design for both 7 pin SATA connector and 15 pin power adapter
- Fan speed control for HIGH, LOW, and AUTO (smart cooling) settings
- Metal case with heavy duty ABS tray and door latch
- Designed for power users and system builder applications, mainly space saving and hot swap usage and for 2.5" HDD or SSD

Model Number	MB324SP-B
Color	Black
Host Interface	4 x 7pin SATA
Drive Fit	4 x 2.5" SATA or SAS (single channel) HDD/SSD
Compatible 2.5" Drive Heights	7mm, 9.5mm & 12.5mm
Device Fit	Single 5.25" half height device bay
Transfer Rate	Up to 6 Gb/sec. (depending on hard drive speed)
Power Input	Single 15pin SATA power port
Insert & Extract connection Via	Direct SAS/ SATA hard drive connection
Structure	Plastic and metal
Drive Cooling	40mm rear cooling fan
Fan Speed Control	High / Low / Auto jumper
Power Indicator	Solid blue LED
HDD Access Indicator	Blinking blue LED
Dimension (L x W x H)	145.8 x 41.3 x 151.1mm
Weight	346.3g
Package Contents	Device, user manual, screws