

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1052620003](#)
Status: **Active**
Overview: [Antennas](#)
Description: ISM 868/915 MHz Antenna, 200.00mm Cable Length

Documents:

3D Model	Packaging Specification PK-105262-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-105262-003-001 (PDF)	Product Literature (PDF)

General

Product Family	Antennas
Series	105262
Component Type	Stand Alone Antenna with Cable
Mates With	73412-0110 Microcoaxial RF, 50 Ohm
Overview	Antennas
Product Literature Order No	987650-7461
Product Name	ISM 868/915 MHz Stand Alone
Protocol	LoRa, Neul, SigFox, Z-Wave, Zigbee
Type	ISM Antenna
UPC	887191106564

Physical

Cable Length	200.00mm
Length	79.00mm
Mounting Style	Adhesive
Net Weight	0.690/g
Packaging Type	Tray
Polarization	Linear
Radiation Pattern	Omnidirectional
Thickness	0.10mm
Width	10.00mm


Electrical

Band#1 F_End (MHz)	870
Band#1 F_Start (MHz)	863
Band#2 F_End (MHz)	928
Band#2 F_Start (MHz)	902
Electrical Connectivity	Cable
Peak Gain (dBi)	0.2 @ 868 MHz, 1.2 @ 915 MHz
Return Loss - S11 (dB)	< -11, < -13
Total Efficiency	> -2.0dB @ 915 MHz, > -3.2dB @ 868 MHz

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-105262-001-001
Product Specification	PS-105262-003-001
Sales Drawing	SD-105262-001-001

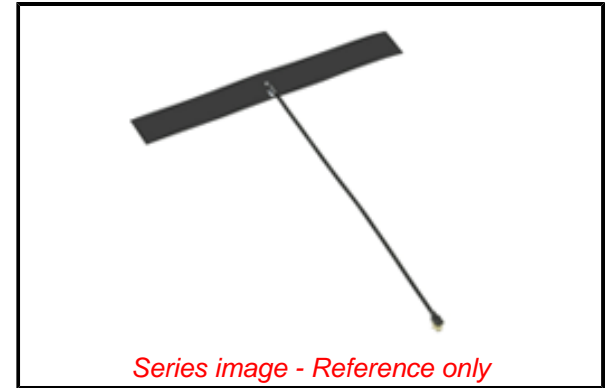

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[105262](#) Series