


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350220002](#)
Status: **Active**
Description: 2.50mm Pitch Board-in Crimp Housing, 2.95mm Height, Right-Angle and Vertical, 2 Circuits, Natural

Documents:	
3D Model	Product Specification PS-35022-003 (PDF)
Drawing (PDF)	Packaging Specification PK-35022-001-001 (PDF)
Product Specification PS-35021-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	35022
Application	Signal
Product Name	Board-in
UPC	800753644458
Physical	
Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Resin	Nylon
Net Weight	0.066/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35022-001-001
Product Specification	PS-35021-001-001, PS-35022-003
Sales Drawing	SD-35022-00**

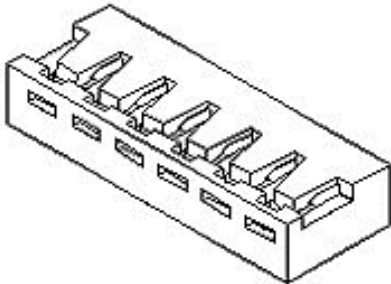

Series image - Reference only

EU ELV Compliant	
EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
Green Image Compliant Not Contained	

Search Parts in this Series
[35022](#) Series

Use With
Straight Terminal [35044-9105](#)
Right
Angle Terminal [35021-1001](#) , [35021-1160](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION