


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0887328802](#)  
**Status:** **Active**  
**Overview:** [USB Products and Solutions](#)  
**Description:** USB On-The-Go (OTG) Shielded I/O Cable Assembly, USB A-to-Mini B, USB 2.0, 1.80m Length, Black

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Packaging Specification PK-88740-012 \(PDF\)](#)

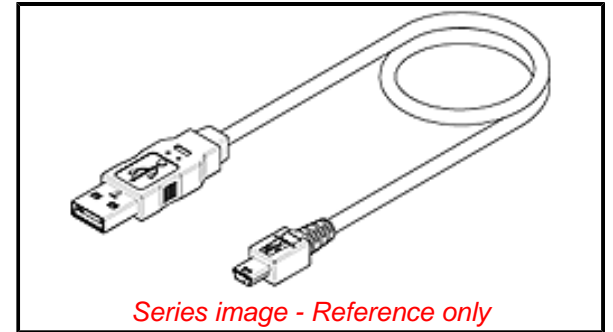

**General**

Product Family	Cable Assemblies
Series	<a href="#">88740</a>
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Mini-B
Overview	<a href="#">USB Products and Solutions</a>
Product Name	USB
UPC	800756208428

**Physical**

Cable Length	1.80m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	66.900/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm, 2.50mm
Plating min - Mating	0.762µm
Plating min - Termination	4.064µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round

**Electrical**

Current - Maximum per Contact	1.0A
Shielded	Yes
Voltage - Maximum	30V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-88740-012
Sales Drawing	SD-887328500

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/61/2018 (27 June 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[88740](#) Series

**Mates With**

USB On-The-Go (OTG) Mini-B Receptacle [54819](#) , [48242](#) , [500075](#) , [67503](#). Universal Serial Bus Shielded Receptacle Type A [67329](#) , [67226](#) , [67230](#) , [89485](#). [54366](#) Universal Serial Bus Shielded I/O Receptacle