
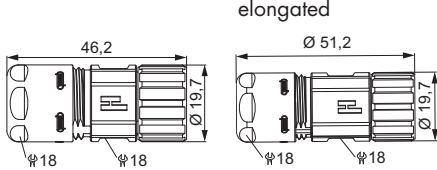

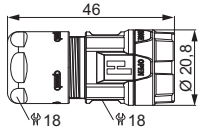

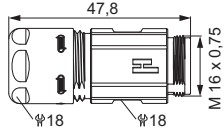

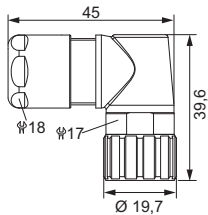


Connectors M 16 / Housing

Straight Connector, Female Thread / elongated *		Cable-Ø	Part Number
		3 – 6 mm (.11 – .23").....7.810.300.000	
		5 – 9 mm (.20 – .35").....7.810.400.000	
		8 – 11 mm (.31 – .43").....7.810.500.000	
		* elongated	
		3 – 6 mm (.11 – .23").....7.811.300.000	
		5 – 9 mm (.20 – .35").....7.811.400.000	
		8 – 11 mm (.31 – .43").....7.811.500.000	
Contacts and inserts page 22 • Assembly instructions page 35 / 36			

Straight Connector, Female Thread TWILOCK		Cable-Ø	Part Number
		3 – 6 mm (.12 – .24").....7.816.300.000	
		5 – 9 mm (.20 – .35").....7.816.400.000	
		8 – 11 mm (.31 – .43").....7.816.500.000	
Contacts and inserts page 22 • Assembly instructions page 35 / 36			

Straight Connector, Male Thread		Cable-Ø	Part Number
		3 – 6 mm (.11 – .23").....7.820.300.000	
		5 – 9 mm (.20 – .35").....7.820.400.000	
		8 – 11 mm (.31 – .43").....7.820.500.000	
Contacts and inserts page 22 • Assembly instructions page 35 / 36			

Right Angle Connector with positioning		Cable-Ø	Part Number
		3 – 6 mm (.11 – .23").....7.831.300.000	
		5 – 9 mm (.20 – .35").....7.831.400.000	
		8 – 11 mm (.31 – .43").....7.831.500.000	
Contacts and inserts page 22 • Assembly instructions page 37			