


KEMET Part Number: SHO-402
(SHO402)

KEMET, SHO, DC Line Filters, Common Mode, 99 uH

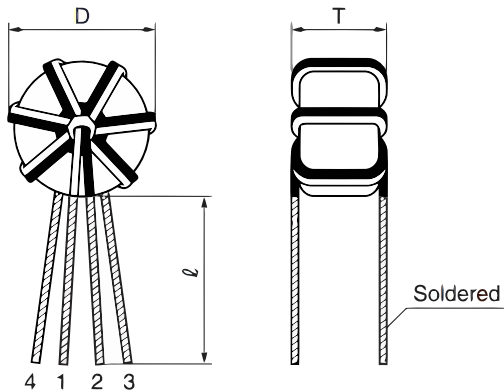

Dimensions

L	7.5mm MAX
T	5mm MAX
H	7.5mm MAX
LL	4mm +/-2mm

Packaging Specifications

Packaging:	Bulk, Box
Packaging Quantity:	6000
Weight:	370 mg

General Information

Series:	SHO
Style:	Through-Hole
RoHS:	Yes

Specifications

Voltage DC:	50 VDC
Inductance:	99 uH
Temperature Range:	-25/+80C
DC Resistance:	120 mOhms