

V-TAC[®]

INNOVATIVE LED LIGHTING

LED Fittings and Tubes

V-TAC's advance grill fixtures are a new generation of linear fittings. Designed with high-caliber materials, these fixtures provide exceptional light levels, are extremely energy efficient and are easy to install. The unparalleled performance of our Grill fittings makes it a cut-above conventional fixtures. It's easy to install function and aesthetic lighting effect gives this new range an amazing potential for retail and residential applications.

These fixtures are the better choice, in terms of performance and aesthetic value, for commercial, retail or residential applications in comparison to conventional fluorescent fixtures.



- Delivering a high lumen output of over 120 lumen per watt
- Designed to deliver a smooth and soft lighting effect
- Options! Available in 60cm, 120cm, 150cm and 180cm
- The push fit connectors make it easy to install
- Five year warranty

5 V-TAC[®] PRO
YEAR WARRANTY

*Suitable for 10-12 hours daily, usage of the product for 24 hours a day would void warranty



120+ LUMENS PER WATT

SUPER EFFICIENT

30 CM - LED Grill Fitting

10W VT-8-10

EAN Code

659 - 3000K Warm White


3800157632140

660 - 4000K Day White

3800157632157

661 - 6400K White

3800157632164

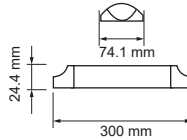

1200
Lumens



>80
CRI



>0.5
PF



<1s
Instant Start



15000
On/Off



260 g
Weight

Voltage/Frequency	LED Type	Beam Angle	Body Type	Dimension	Life span	Box Qty.
AC:220-240V,50HZ	SMD	110°	Plastic	300 x 74.1 x 24.4mm	30000 Hours	10

120+ LUMENS PER WATT

SUPER EFFICIENT

60 CM - LED Grill Fitting

20W VT-8-20

EAN Code

662 - 3000K Warm White


3800157632171

663 - 4000K Day White

3800157632188

664 - 6400K White

3800157632195

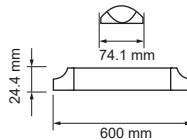

2400
Lumens



>80
CRI



>0.5
PF



<1s
Instant Start



15000
On/Off



420 g
Weight

Voltage/Frequency	LED Type	Beam Angle	Body Type	Dimension	Life span	Box Qty.
AC:220-240V,50HZ	SMD	110°	Plastic	600 x 74.1 x 24.4mm	30000 Hours	10

120+ LUMENS PER WATT

SUPER EFFICIENT

120 CM - LED Grill Fitting

40W VT-8-40

EAN Code

665 - 3000K Warm White


3800157632201

666 - 4000K Day White

3800157632218

667 - 6400K White

3800157632225

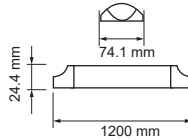

4800
Lumens



>80
CRI



>0.9
PF



<1s
Instant Start



15000
On/Off



840 g
Weight

Voltage/Frequency	LED Type	Beam Angle	Body Type	Dimension	Life span	Box Qty.
AC:220-240V,50HZ	SMD	110°	Plastic	1200 x 74.1 x 24.4mm	30000 Hours	10

120+ LUMENS PER WATT

SUPER EFFICIENT

150 CM - LED Grill Fitting

50W VT-8-50


EAN Code

668 - 4000K Day White

3800157632232

669 - 6400K White

3800157632249

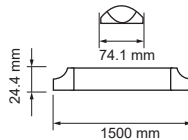

6000
Lumens



>80
CRI



>0.9
PF



<1s
Instant Start



15000
On/Off



1000 g
Weight

Voltage/Frequency	LED Type	Beam Angle	Body Type	Dimension	Life span	Box Qty.
AC:220-240V,50HZ	SMD	110°	Plastic	1500 x 74.1 x 24.4mm	30000 Hours	10

120+ LUMENS PER WATT

SUPER EFFICIENT

180 CM - LED Grill Fitting

60W VT-8-60


EAN Code

3800157632256

670 - 4000K Day White

671 - 6400K White

3800157632263

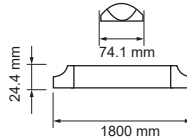

7200
Lumens



>80
CRI



>0.9
PF



<1s
Instant Start



15000
On/Off



1200 g
Weight

Voltage/Frequency	LED Type	Beam Angle	Body Type	Dimension	Life span	Box Qty.
AC:220-240V,50HZ	SMD	110°	Plastic	1800 x 74.1 x 24.4mm	30000 Hours	10

