


# AB-AV-933-N IP65 ANTI-VANDAL PUSH BUTTON

SWITCHES

## Specifications

Specifications		AB-AV-933-N
Terminal type		Screw terminals
Switching		1NO/1NC Latching
Panel cut out		19mm
Switch rating		5A(2) 250VAC / 5A(2) 12/24VDC
Contact resistance		≤50MΩ
Insulation resistance		≥1000MΩ
Dielectric strength		2000VAC
Operating temperature		-25°C~+55°C
Mechanical life		≥1,000,000 cycles
Electrical life		≥50,000 cycles
Panel thickness		1~10mm
Torque		0.8Nm max applied to nut
Operation pressure		4N approx
Operation travel		2.5mm approx
IP degree		IP65
Material: Contact		Silver alloy
Button/Body		Stainless steel
Base		PA/PC
Shock resistance		≥10g

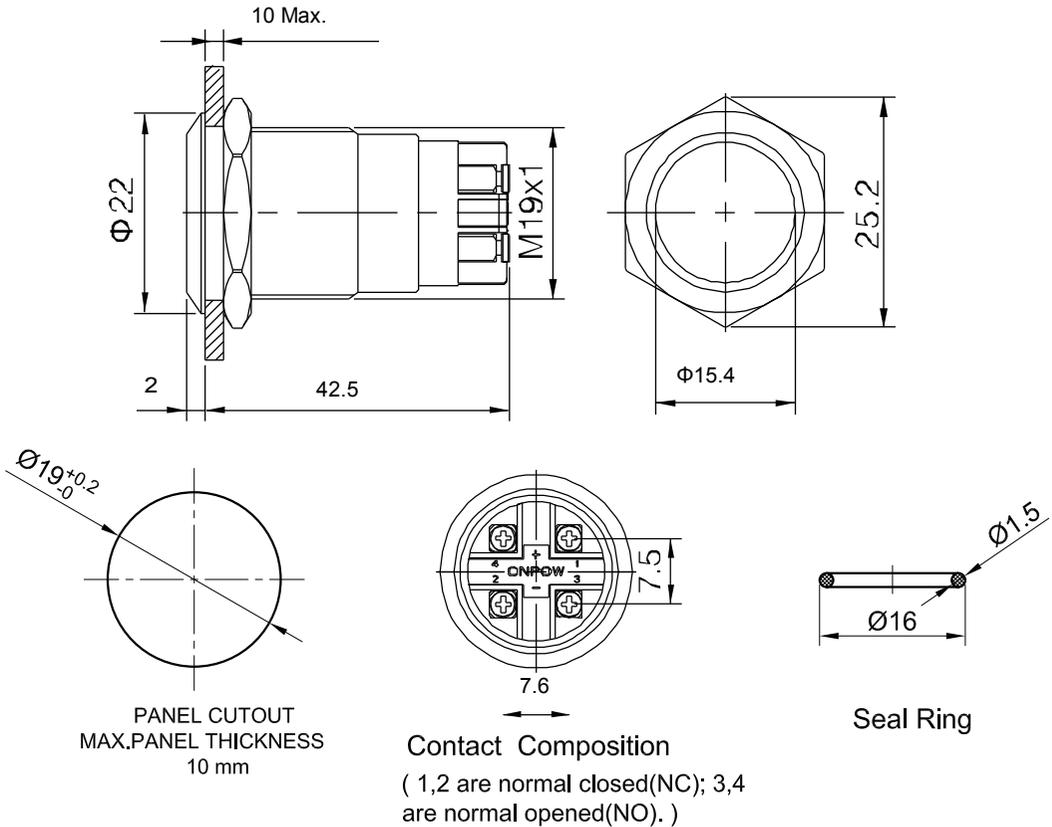

ROHS Compliant



ALAN BUTCHER COMPONENTS LTD

**Alan Butcher Components Ltd**

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

[www.abcomponents.co.uk](http://www.abcomponents.co.uk)