

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1451300510

Status:


Active

Overview:

Nano-Fit Power Connectors

Description:

Nano-Fit-to-Nano-Fit Off-the-Shelf (OTS) Cable Assembly, Single Row, 1.0m Length, 5 Circuits, Black

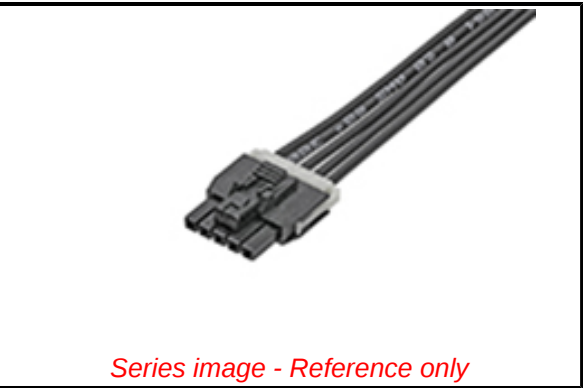

Documents:

[Drawing \(PDF\)](#)

[Product Literature \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	145130
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Nano-Fit-to-Nano-Fit
Overmolded	No
Overview	Nano-Fit Power Connectors
Product Literature Order No	987651-6143
Product Name	Nano-Fit OTS
UPC	191130118922
Physical	
Cable Length	1.0m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Conductivity Copper
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Material - Resin	Nylon
Net Weight	36.460/g
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.57mm
Wire Size AWG	20
Wire/Cable Type	UL 1061
Electrical	
Current - Maximum per Contact	6.5A
Voltage - Maximum	250V AC (RMS)
Material Info	
Reference - Drawing Numbers	
Sales Drawing	4000095320-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

145130 Series

Mates With

Nano-Fit Headers 105309 , 105311 , 105324

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION