


Part Number	Finish	Size	Weight
R2410Z	Zinc	254mm/ 10"	0.743Kg/1.64Lb
R2012Z	Zinc	305mm/ 12"	0.89Kg/1.96Lb
R2414Z	Zinc	356mm/ 14"	1.048Kg/2.31Lb
R2016Z	Zinc	406mm/ 16"	1.07Kg/2.36Lb
R2018Z	Zinc	457mm/ 18"	1.35Kg/2.98Lb
R2020Z	Zinc	508mm/ 20"	1.49Kg/3.28Lb
R2022Z	Zinc	559mm/ 22"	1.67Kg/3.68Lb
R2024Z	Zinc	610mm/ 24"	1.82Kg/4.01Lb
R2026Z	Zinc	660mm/ 26"	2.0Kg/4.41Lb
R2028Z	Zinc	712mm/ 28"	2.13Kg/4.7Lb

R2010 - R2028 Drawer Runners

Drawer Slide. Trigger Release Disconnect.
Sold in Pairs.
Load capacity 35Kg/77Lbs per pair.
See Right for sizes

Material: Steel

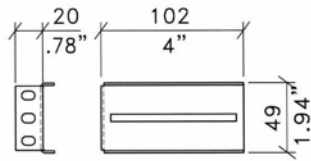


R1209/01

Bracket for Rack mounting Drawer Slides.
Suits R2010 - R2028 or R2410 - R2414 Drawer Slides (Not Included)

Material: 1.5mm/ 16 gauge Steel

Part Number	Description
R1209/01	

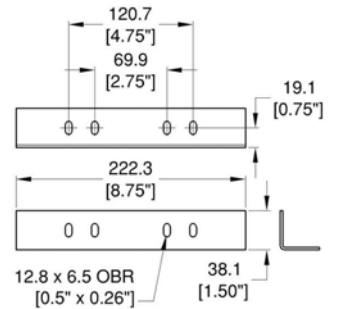

6183BK

Steel Angle with 8 holes.

Material: 2.5mm /1/8\"/>


Part Number	Finish	Description
6183BK	Black	



R2510

Rack mount Wall Bracket. For mounting 19" racking equipment on walls or under tables.

Part Number	Finish	Size (U)
R2510-1U	Black	1U
R2510-2U	Black	2U
R2510-3U	Black	3U
R2510-4U	Black	4U

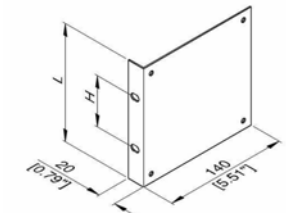

R1206

Rack Mounting Brackets, Black.
Sold individually

Material: 1.5mm/ 16 gauge Steel

Part Number	Size (U)	Weight
R1206/1U	1U	0.082Kg/0.18Lb
R1206/2U	2U	0.162Kg/0.36Lb
R1206/3U	3U	0.245Kg/0.54Lb
R1206/4U	4U	0.353Kg/0.78Lb