

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1600133041](#)  
**Status:** **Active**  
**Overview:** [stAK50h Connector System](#)  
**Description:** stAK50h 2 Bay Infotainment Hybrid Header, 56 Circuits, Bay A 28 Circuit Header, Key 4, Gray; Bay B 28 Circuit Header, Key 1, Gray; 2.50mm PC Tail Length, Tube

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-160013-001-001 \(PDF\)](#) [Product Literature \(PDF\)](#)

**General**

Product Family	PCB Headers
Series	<a href="#">160013</a>
Application	Power, Signal, Wire-to-Board
Overview	<a href="#">stAK50h Connector System</a>
Product Literature Order No	987651-5191
Product Name	stAK50h
UPC	889056647496

**Physical**


Breakaway	No
Circuits (Loaded)	56
Circuits (maximum)	56
Color - Resin	Gray
Durability (mating cycles max)	10
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Tin over Nickel
Material - Plating Termination	Tin over Nickel
Material - Resin	SPS
Net Weight	12.840/g
Number of Rows	5
Orientation	Right Angle
PC Tail Length	2.50mm
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Tube
Pitch - Mating Interface	2.00mm, 4.00mm
Pitch - Termination Interface	2.00mm, 4.00mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Yes
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole - Compliant Pin

**Electrical**

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	500V DC

**Material Info**

**Reference - Drawing Numbers**

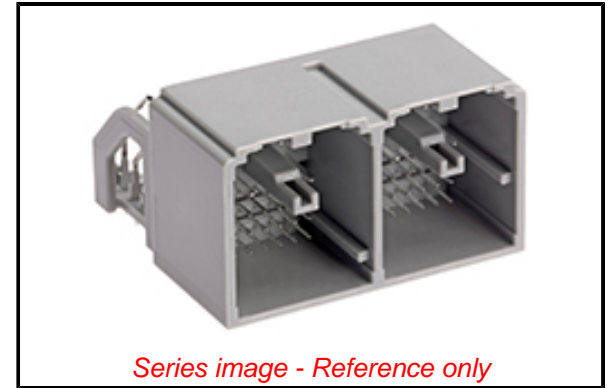

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/61/2018 (27 June  
2018)

**Halogen-Free**

**Status**

**Not Relevant**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[160013 Series](#)

**Mates With**

[stAK50h Receptacle Assembly 160014](#)

This document was generated on 08/23/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**