

PDJLT40

PYLE
PyleUSA.com



VISIT US ONLINE:

*Have a question?
Need service or repair?
Want to leave a comment?*


PyleUSA.com/ContactUs

PYLE



MINI MOVING HEAD LIGHT **User Manual**

OPERATE FUNCTION :

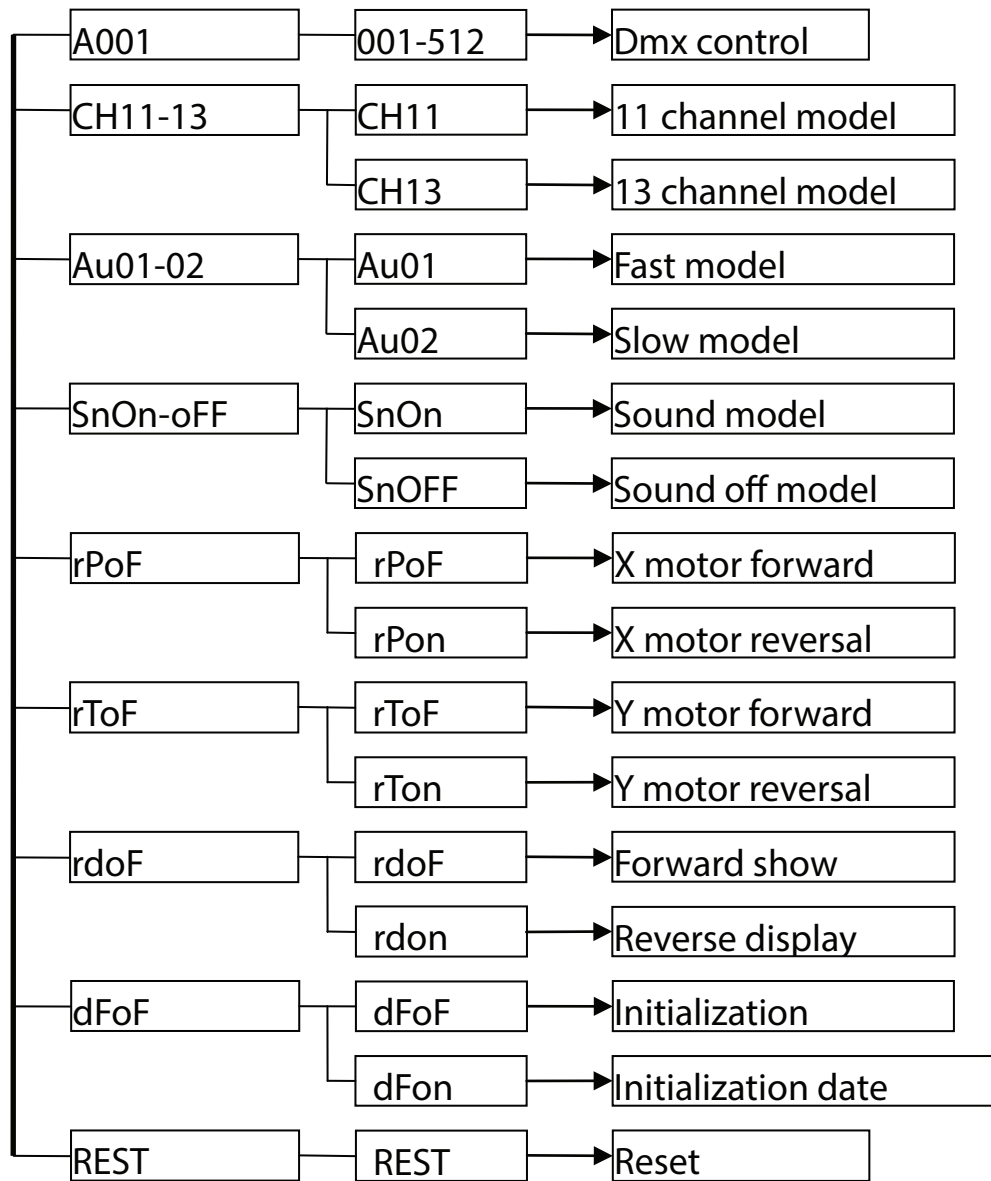

PDJLT40 FUNCTION :

13 Channel mode

Channel		Function
1	0-255	Level
2	0-255	Level of fine-tuning
3	0-255	Vertical
4	0-255	Vertical of fine-tuning
5	0-255	Speed
6	0-255	Dimming
7	0-255	Strobe
8	0-255	Red dimming
9	0-255	Green dimming
10	0-255	Blue dimming
11	0-255	White dimming
12	0-255	Self-propelled
13	150-250	Reset

11 Channel Mode

Channel		Function
1	0-255	Level
2	0-255	Level of fine-tuning
3	0-255	Vertical
4	0-255	Vertical of fine-tuning
5	0-255	Speed
6	0-255	Dimming
7	0-255	Strobe
8	0-255	Red dimming
9	0-255	Green dimming
10	0-255	Blue dimming
11	0-255	White dimming

TECHNICAL REFERENCE:

Voltage: AC900-240V, 50/60Hz

POWER: 20W

Light Source: 1PCS* 10W RGBW 4 IN 1

Control modes: Auto-run, DMX512, voice control, Master-slave model

DMX Channels: 11/13 CH

Package: 8PCS/Carton

Inner Package: 240*180*180 MM

Out Package: 500*380*390 MM

N.W.: 17.2 kg/carton

G.W.: 20kg/carton