

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0887328602

Status:


Active

Overview:

USB Products and Solutions

Description:

USB On-The-Go (OTG) Shielded I/O Cable Assembly, USB A-to-Mini B, USB 2.0, 1.0m Length, Black

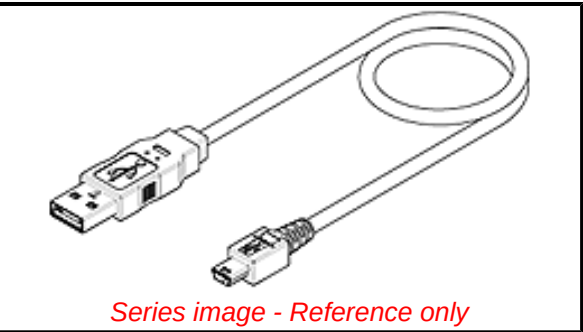

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	88740
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Mini-B
Overview	USB Products and Solutions
Product Name	USB
UPC	800756208954
Physical	
Cable Length	1.0m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	40.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm, 2.50mm
Plating min - Mating	0.762µm
Plating min - Termination	4.064µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round
Electrical	
Current - Maximum per Contact	1.0A
Shielded	Yes
Voltage - Maximum	30V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	060
Lead-freeProcess Capability	N/A
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-887328500

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

88740 Series

Mates With

USB On-The-Go (OTG) Mini-B Receptacle

54819 , 48242 , 500075 , 67503. Universal

Serial Bus Shielded Receptacle Type

A 67329 , 67226 , 67230 , 89485.

54366 Universal Serial Bus Shielded I/O

Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION