

Thermodata Components

[About](#)
[Modular Terminal Strips](#)
[High Barrier Terminal Strips](#)
[Website Terms of Use](#)

Modular Terminal Strips

A new concept in Terminal Strips


Mix and match: A new concept to help solve your packaging problems. Now you can mix terminations with "snap" together modules to provide permanent configurations

Reduce your Inventory

Make up what you want when you want to avoid "dead" stock

Technical Data

Material	High impact thermoplastic
Terminal plates	Brass, nickel plated
Terminal Tags	Brass, tin coated
Screws	6/32 UNC, Binder Head, nickel plated 15 amps - 750 V d.c. or a.c. peak
Rating	Temperature range -55°C to +100°C

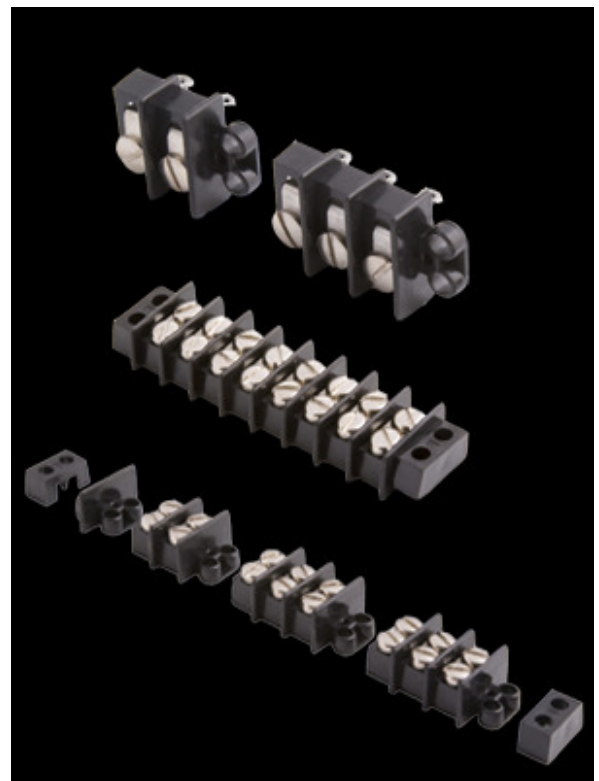


RoHS Compliant

Dimensions

All dimensions are in millimetres

Drop through solder terminals

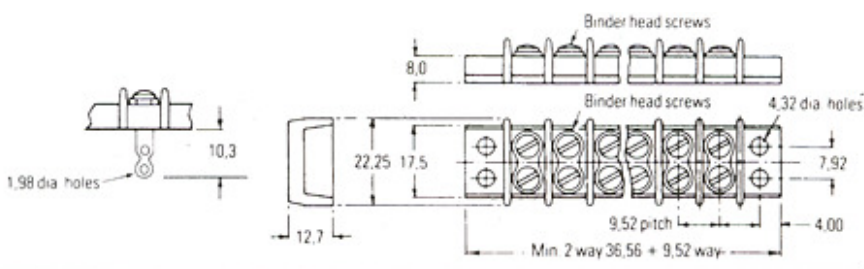

Ordering Information



**Twin
Terminal
2 Way**

R44 38



**Twin
Terminal
3 Way**

R44 41



**Drop-Through
Solder
Terminal 2 Way**

R44 39



**Drop-Through
Solder
Terminal 3 Way**

R44 42



**Joining
Segment**

P44 44



End Fix Cover

**Plain - P44 45
Screw Fix - R44
46**

© Thermodata Components - All Rights Reserved
PO Box 140, Sandy, SG19 2WL.
Telephone: +44 (0) 1767 683697 Fax: +44 (0) 1767 683347
Email: sales@thermodata.co.uk