



LIGHT STAND WITH PAR PROJECTOR, STROBE, MOON & LASER

DJLIGHT85LED

Light set that combines various Plug & Play light effects.


- PAR projector fitted with 12x 1W RGBW LED
- Stroboscope fitted with 120 white SMD LED
- Moon effect fitted with 60x 5mm RGBWA LED
- Red & green laser
- Light stand
- Remote control
- Auto, sound, DMX or remote-controlled operation

**EAN
CODE**

**5420047136336
15-1194**

SPECIFICATIONS TECHNIQUES

Power supply	110-240~50/60Hz
Consumption	60W
Laser	Green: 30mW 532nm; Red: 100mW 650nm
Strobe	120x white SMD LEDs
PAR	12 x 1W RGBW LEDs
Moon	60 x 5mm RGBWA LEDs
Beam angle	Auto, sound, DMX512, remote control
Operation	25°
Max. height of the stand	202cm
Total dimensions	74 x 21 x 202cm
Total weight	5kg

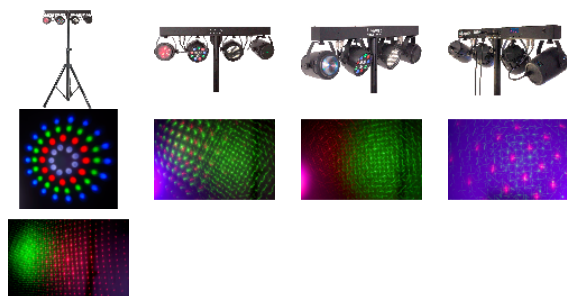

LOGISTICS VALUES

Packaging height	915 cm
Packaging width	185 cm
Packaging depth	380 cm
Packaging volume	0.064 m ³
Packaging gross weight	7000 kg
Qty per master carton	1
EAN14 code	54200471363364
Customs code	94054091

